


EVSG-ORD 50 BK

Stop end with mounted O-Ring, polyamide, RAL 9005, M50

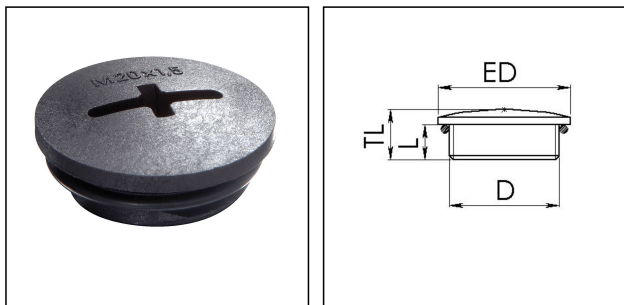

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Polyamide, fibre reinforced
Material sealing gasket	EPDM
Temp. range min	-40 °C
Temp. range max	100 °C
Glow wire test	650 °C
Protection class	IP66 / IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	50
Lead	1,5
Length screw-in thread L	10 mm
Total length TL	15 mm
External diameter ED	56 mm
Product Color	RAL 9005
Order no. RAL 9005	10064648
Type	EVSG-ORD 50 BK
Packing unit	50
EAN number	4007685646482
Tariff number	39269097
ETIM-Classification	EC000032

Recommended accessories

EMUG 50 BK	10061786
-------------------	----------

02.09.2025


Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

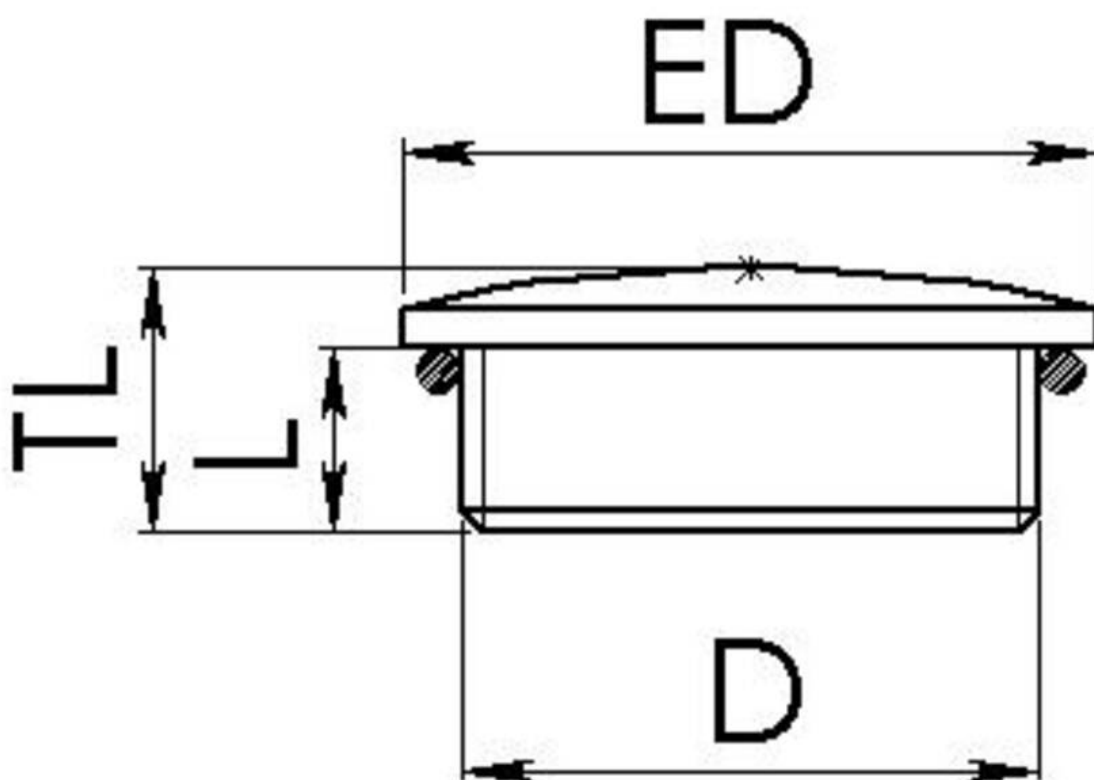

Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com