


EVSG-ORD 63 BK

Stop end with mounted O-Ring, polyamide, RAL 9005, M63

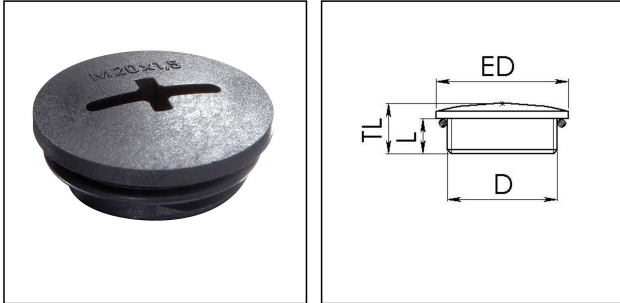

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Polyamide, fibre reinforced
Material sealing gasket	EPDM
Temp. range min	-40 °C
Temp. range max	100 °C
Glow wire test	650 °C
Protection class	IP66 / IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	63
Lead	1,5
Length screw-in thread L	12 mm
Total length TL	17 mm
External diameter ED	70 mm
Product Color	RAL 9005
Order no. RAL 9005	10064649
Type	EVSG-ORD 63 BK
Packing unit	25
EAN number	4007685646499
Tariff number	39269097
ETIM-Classification	EC000032

Recommended accessories

EMUG 63 BK	10061787
-------------------	-----------------

02.09.2025


Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

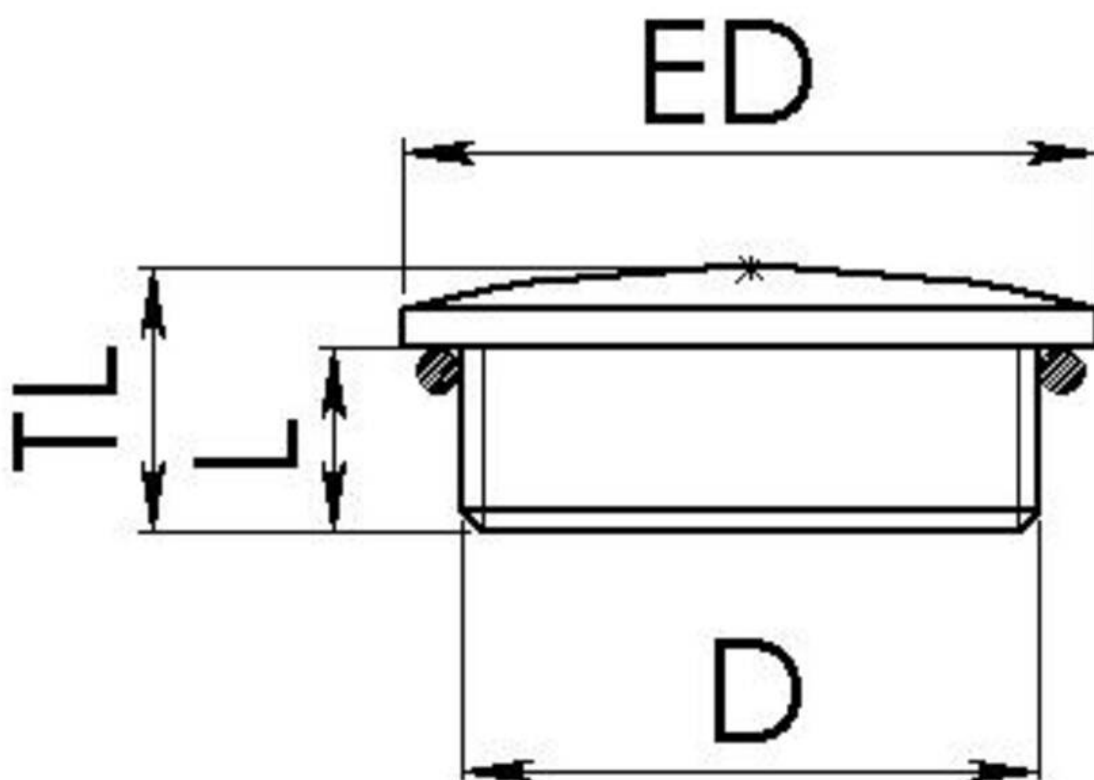

Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

Other technical data on request / subject to change without notice