

788/ESKV 25 / 221-2411 BK

Cable joint with cable glands, plastic, RAL 9005, IP68



Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



Material	Polypropylene
Material cable gland	Polyamide
Temp. range min	-30 °C
Temp. range max	85 °C
Protection class	IP68 (5 bar 30 min)
Glow wire test	750 °C
Terminals/poles	3 x 4 mm ²
Ø cable diameter min	9 mm
Ø cable diameter max	17 mm
Key width SW1	27 mm
Key width SW2	29 mm
Product Color	RAL 9005
Total length TL	134 mm
Order no. RAL 7035	10112270
Type	788/ESKV 25 / 221-2411 BK
Packing unit	15
ETIM-Classification	EC001169
EAN number	4007686294729
Tariff number	85369010

02.09.2025


Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

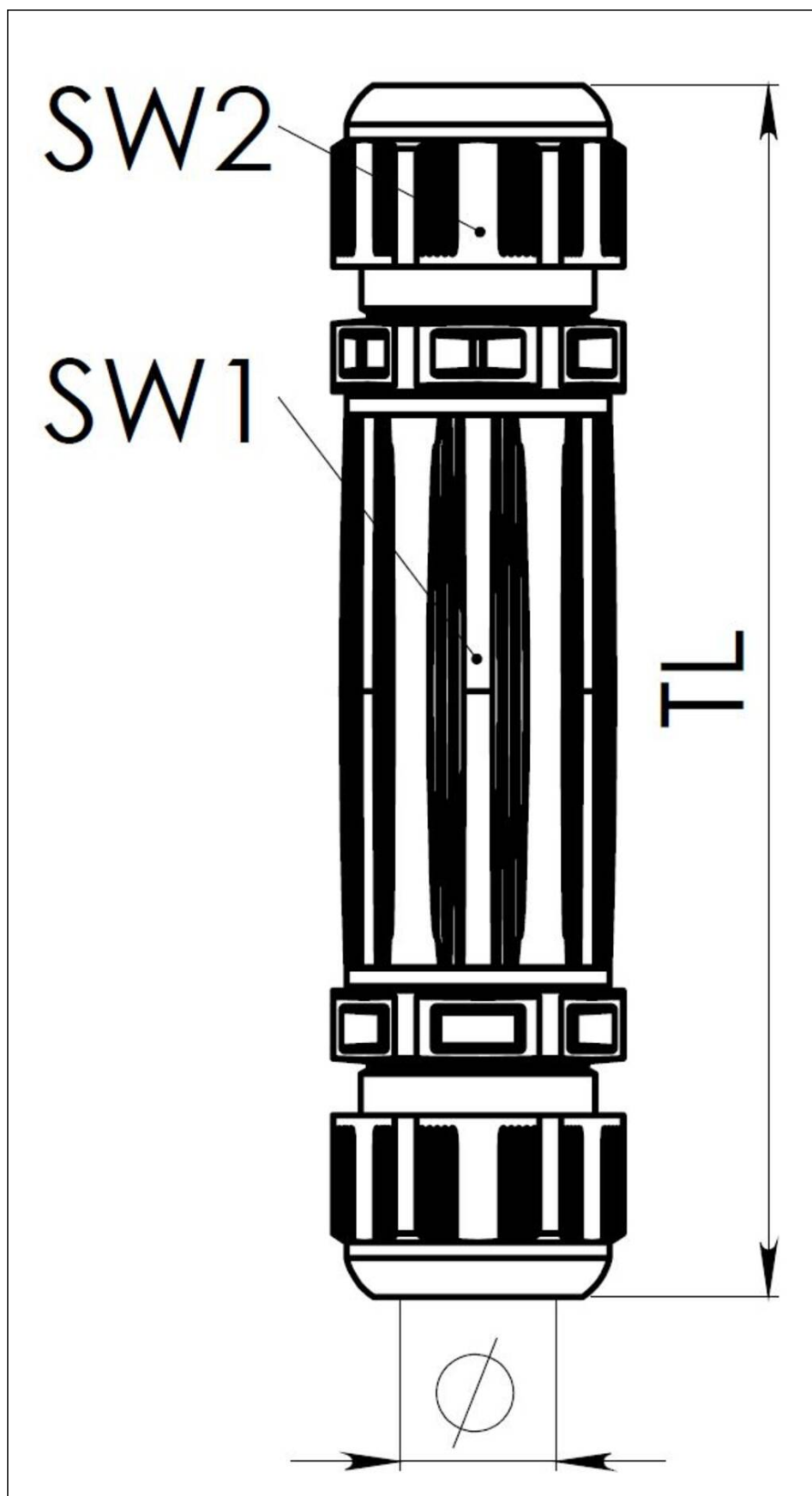

Your Contact:

WISKA Hoppmann GmbH

Kisdorfer Weg 28 · 24568 Kaltenkirchen · Germany

☎ +49-4191-508-0 · 📠 +49-4191-508-209

contact@wiska.de · www.wiska.com

Other technical data on request / subject to change without notice