


ShieldGLAND Standard M25

ShieldGLAND Standard M25 Brass locknut, Earth tag

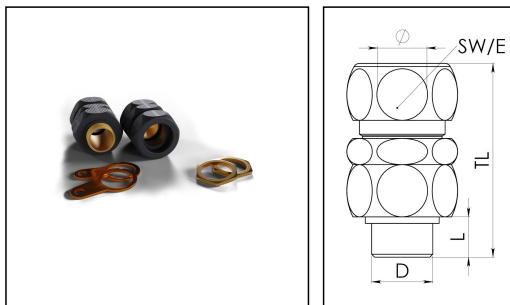

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.

Material sealing gasket	TPE
Temp. range min	-40 °C
Temp. range max	120 °C
Protection class	IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	25
Lead	1,5
Length screw-in thread L	13 mm
Ø cable diameter min	17 mm
Ø cable diameter max	28 mm
Ø cable below cable shield max	17 mm - 21 mm
Key width SW	41 mm
Collar diameter (E)	46 mm
Total length TL	61 mm - 68 mm
Type	ShieldGLAND Standard M25
WISKA-Order no.	10112392
Packing unit	2

Remarks:

Complete with Brass locknut and earth tag

LSF = Low smoke and fume

LSOH = Low smoke zero halogen

02.09.2025


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

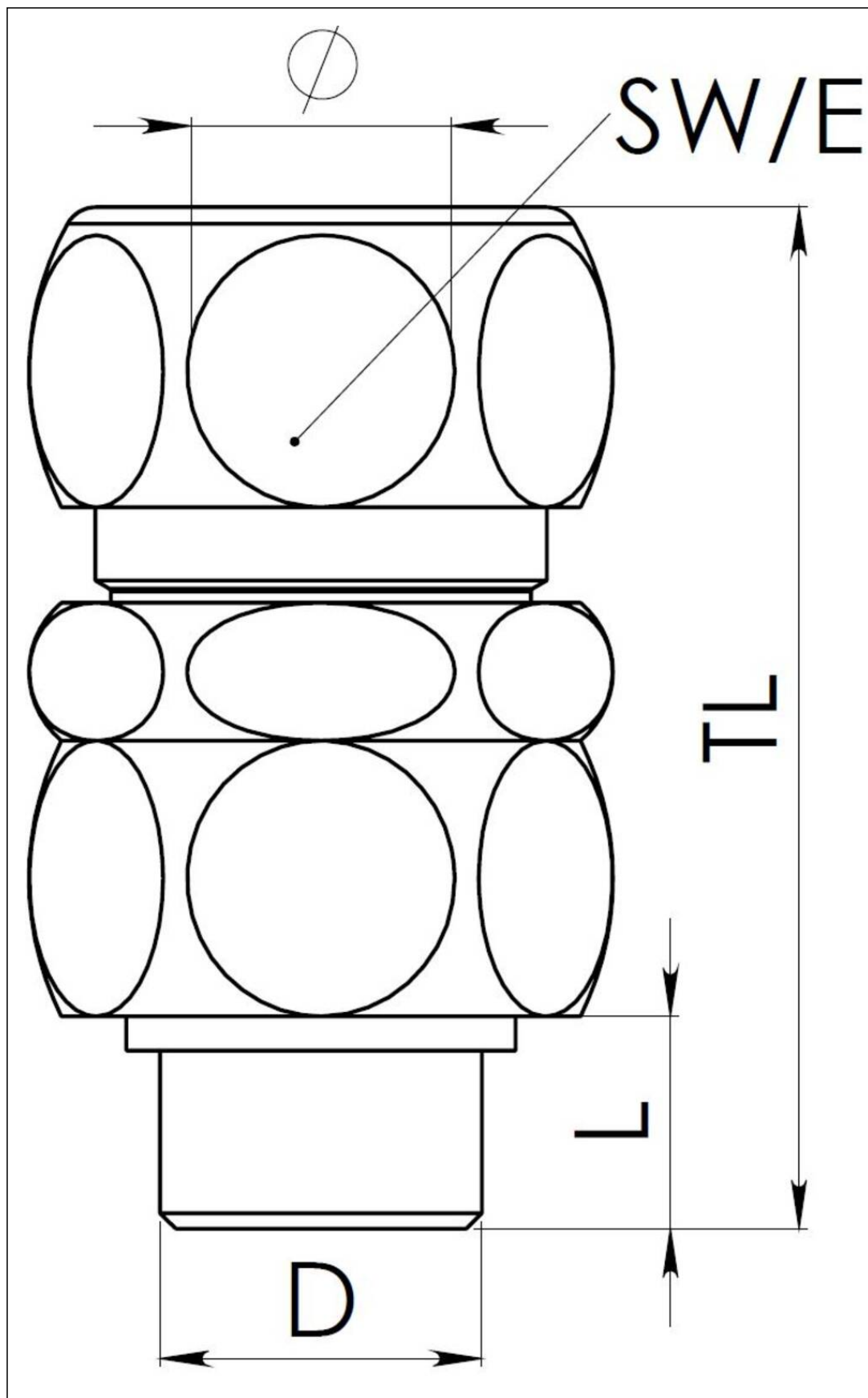

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice