


ShieldGLAND Standard M32

ShieldGLAND Standard M32 Brass locknut, Earth tag

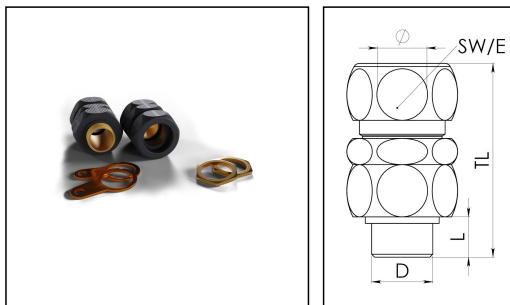

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.

Material sealing gasket	TPE
Temp. range min	-40 °C
Temp. range max	120 °C
Protection class	IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	32
Lead	1,5
Length screw-in thread L	13 mm
Ø cable diameter min	24 mm
Ø cable diameter max	36 mm
Ø cable below cable shield max	24 mm - 30 mm
Key width SW	50 mm
Collar diameter (E)	56 mm
Total length TL	66 mm - 74 mm
Type	ShieldGLAND Standard M32
WISKA-Order no.	10112393
Packing unit	2

Remarks:

Complete with Brass locknut and earth tag

LSF = Low smoke and fume

LSOH = Low smoke zero halogen

02.09.2025


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

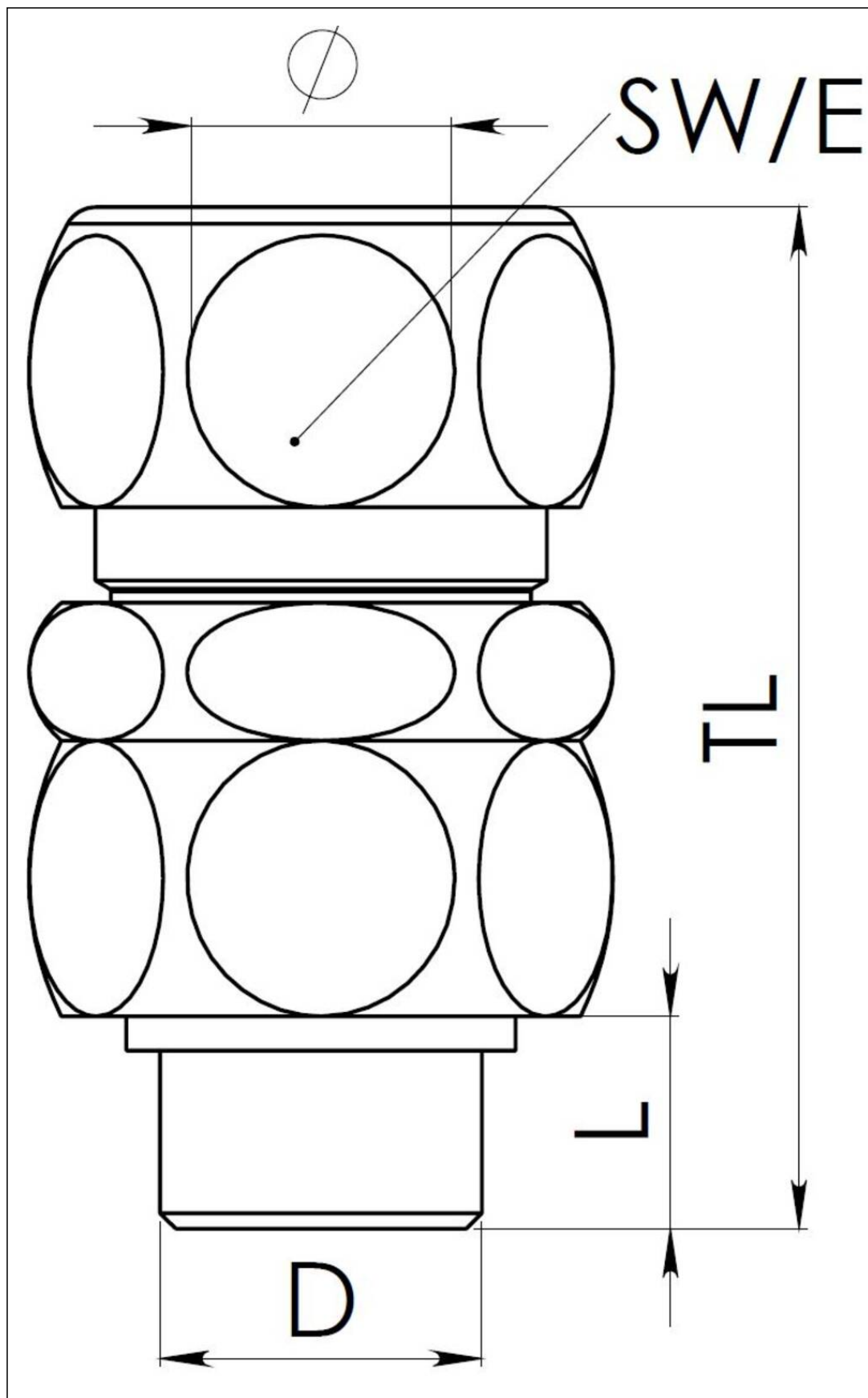

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice