


ShieldGLAND Pro M20S

ShieldGLAND Pro M20S Brass locknut, E-Spring, earth fly lead

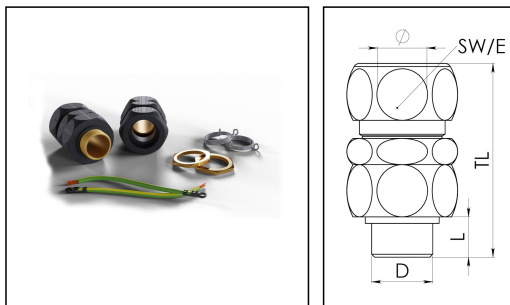

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.

Material sealing gasket	TPE
Temp. range min	-40 °C
Temp. range max	120 °C
Protection class	IP68 (5 bar 30 min)
Thread type	M
Ø Connection thread D	20
Lead	1,5
Length screw-in thread L	11 mm
Ø cable diameter min	7 mm
Ø cable diameter max	16 mm
Ø cable below cable shield max	7 mm - 11 mm
Key width SW	27 mm
Collar diameter (E)	30 mm
Total length TL	57 mm - 63 mm
Type	ShieldGLAND Pro M20S
WISKA-Order no.	10112394
Packing unit	2

Remarks:

Complete with Brass locknut, E-Spring
and earth fly lead

LSF = Low smoke and fume

LSOH = Low smoke zero halogen

02.09.2025


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

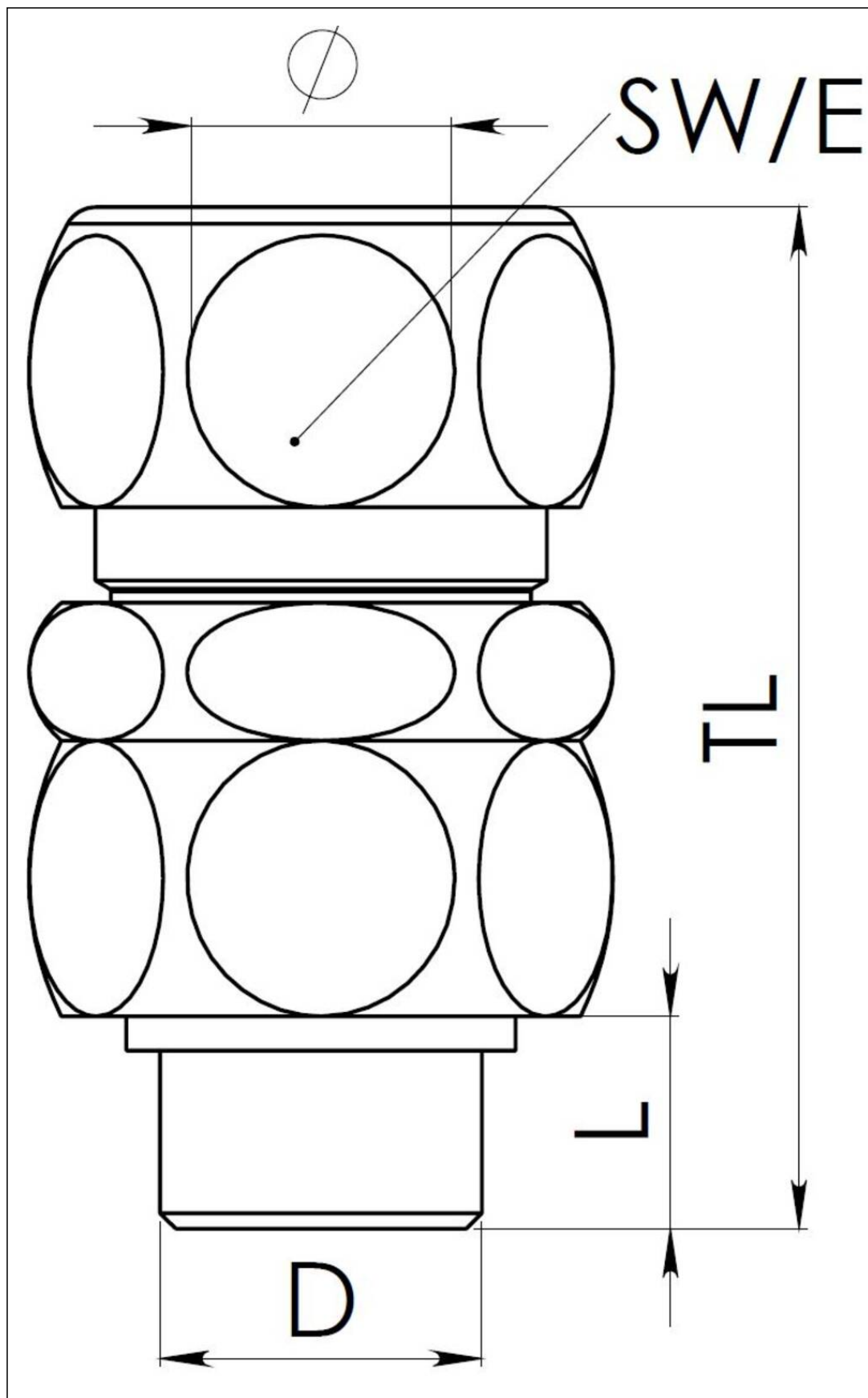

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice