


SH0425/W

SHARK T Branch

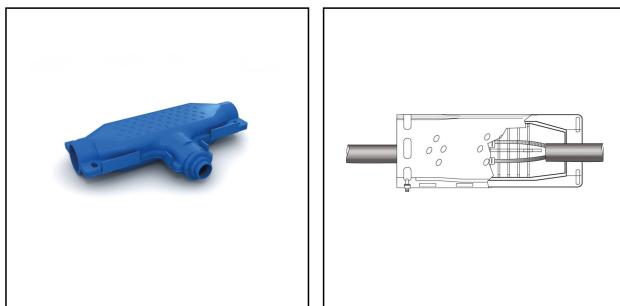

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.

Material	Polyamide
Filling	Silicone
Temp. range min	-20 °C
Temp. range max	90 °C
Glow wire test	self-extinguishing
Voltage	0,6 kV - 1 kV
Quantity of cable	1
Type	SH0425/W
UK-Number	10111406
WISKA-Order no.	10111406
Packing unit	1
ETIM-Classification	EC001169

Remarks:

Cable Size: Main Cable up to 150 mm Branch cable up to 50 mm

LxBxH: 210x125x49 mm

Description:

SHARK T BRANCH Pre-filled gel insulated T joint for branch connection.

Additional Info:

Ready to use, re-enterable, no mixing or pouring, immediate operation, excellent electrical insulation, good mechanical strength, no expiry date.

02.09.2025


Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

 +44-12-08816062 ·  +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

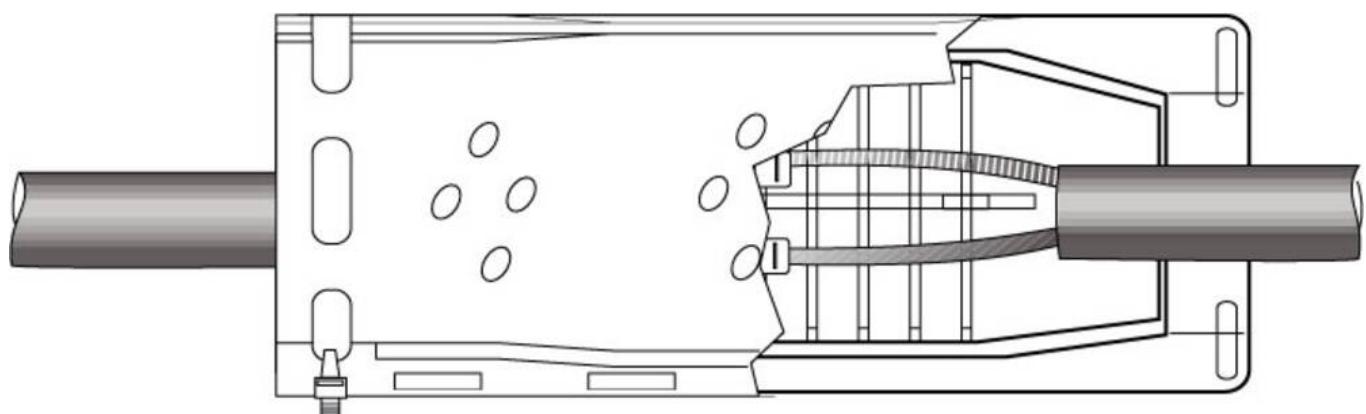

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · ✉ +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk