


SK133

BRANCH Series Y

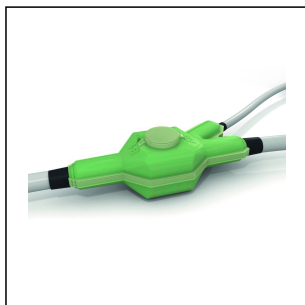

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.

Filling	Resin
Voltage	0,6 kV - 1 kV
Ø cable diameter min	13 mm
Ø cable diameter max	45 mm
Quantity of cable	5
Type	SK133
UK-Number	SK133
WISKA-Order no.	10108976
Packing unit	1

Remarks:

Cores: 5

Min - Max Cross Section Main Cable mm²: 10 - 35 mm²

Min - Max Cross Section Branch Cable mm²: 2.5 - 35 mm²

Shelf life: 3 years

IP X8

Description:

SUBMARINE Branch Series allows Y branch jointing of .6/1 kV single and multicore cables up to five cores. Kit includes 2 transparent half-shells, 2 component resin, Direct Injection casting system allowing pre-mixed resin to be injected inside the joint, 5 core terminal block, earth braid and constant force roll springs.

Additional Info:

Perfect for cable ducts, overhead, underground and underwatert installations as well as public lightning systems. Excellent electrical insulation and mechanical strength. Available with final solid state (green) and re-enterable resin (yellow).

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

03.09.2025

Your Contact:

WISKA UK Ltd.

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

 +44-12-08816062 ·  +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk