



Item Code - DC2U/300

2U Data Cabinet 300 Deep (MiniCab™)



- 19" rack mount, Ideal for a Patch Panel or where only 1U or 2U is required
- Comes with rear mounting bracket and part open back for easy installation
- Equipped with front mounting posts with a lockable front door
- Knockout cable entry top and bottom. Can accept a bespoke Brush Plate(not supplied)
- 300mm deep and will accept small routers and other similar devices

The MiniCab™ was developed for situations where one or two pieces of equipment are being installed and a professional finish is required.

It comes with a wall mounting bracket for easy install with additional locating fixing holes also on the cabinet if required. For the cable entry It has an open back or top and bottom knock out options . A Brush plate can be purchased separately to keep the dust out and offering a neat finish rather than a visible opening (see image and part code below)

DVRs in general need 400mm or more depth if you take the cables into account , so this product is not really suitable for such items.




MiniCab

General

Sale Unit	Cardboard Box
Barcode	5028088014974
Commodity Code	9403208000 Made In China
Dimension Packed	180x575x345 mm Height Width Depth
Dimension loose	135x530x300 mm Height Width Depth
Weight Packed	6.15 kg
Weight Loose	5.35 kg
Max load	20 kg
Fixing	Screw Holes/Wall Bracket

Technical

IP Rating	IP20
Frame	1.2mm Steel
Mounting post	1.5mm steel
Other parts	1mm
Color	RAL9004 Texture Powder Coated (Signal Black/Charcoal)

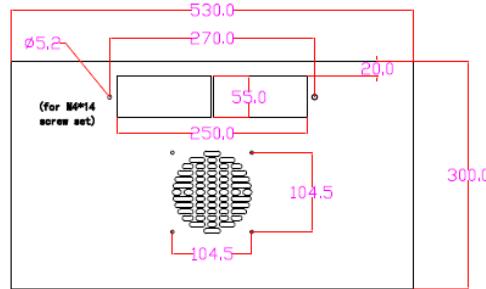
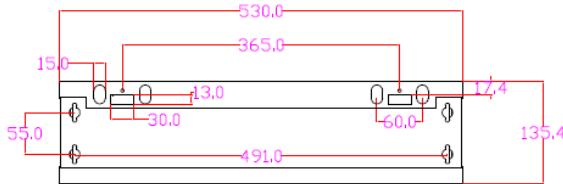
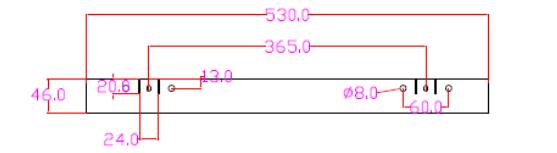


KAUDEN

DO NOT SCALE

UNIT:mm

DATE:2-12-2022

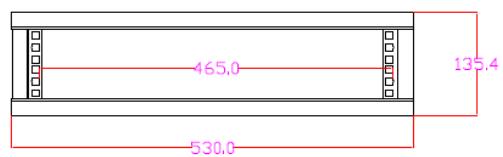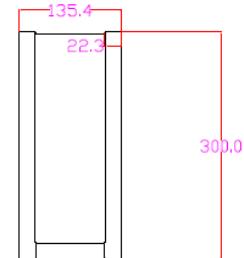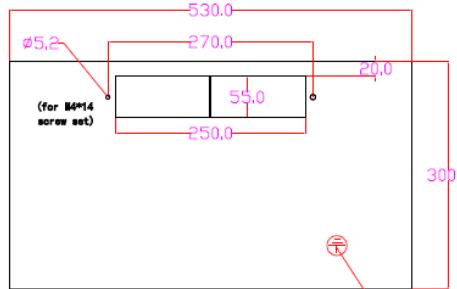

Earth point

Intellectual property rights that subsisting in this product range are the ownership of P.B.C Ltd and this includes any Non-Registered Design Right. 1 Feb 2023