



Item code – POD56V4

GOP Box - Four Outlet 56mm Height , Dual Grommet option



- Allowing either of two size grommet holes , 25mm or 32mm
- Reversible lid to blank off whichever grommet hole is not required
- 56 mm height , 1.2mm Steel Construction
- Four 6C-25x38mm outlets in a vertical orientation
- Keyed gland entry slot

Also known as a GOP Box , Grid Outlet Position or POD box it is ideal for bringing data to the desk from a sub floor environment, normally using flexible conduit and floor access grommets.

GOP boxes are designed to accommodate 6C modules which are 25x38mm in size and commonly known as floor box modules. The apertures are all placed in a Vertical orientation to allow easier access for cables.


The big advantage of this design is that the box itself allows either of two different grommet holes to save carrying different types

General

Sale Unit	Cardboard Box	
Barcode	5028088015384	
Weight Packed	0.47 Kg	
Dimension Packed	70x70x185mm	
	Height Width Depth	
Dimension loose	56x64x191mm	see drawing below
Commodity Code	Commodity Code	94032080

For Trade and Bulk buyers

Carton Quantity	20
Dimension	38.x20x31.5 cm
NW	11 kg
NW	12 kg

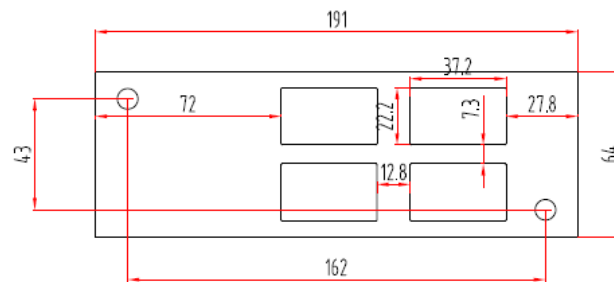

KAUDEN
Steel thickness 1.2mm
DO NOT SCALE
UNIT:mm
DATE:06-02-2023

