



Item code – POD70V2

GOP Box - Two Outlet 70mm Height , Dual Grommet option



- Allowing either of two size grommet holes , 20mm or 25mm
- Reversible lid to blank off whichever grommet hole is not required
- 70mm height , 1.2mm Steel Construction
- Two 6C-25x38mm outlets in a vertical orientation
- Keyed gland entry slot

Also known as a GOP Box , Grid Outlet Position or POD box it is ideal for bringing data to the desk from a sub floor environment, normally using flexible conduit and floor access grommets.

GOP boxes are designed to accommodate 6C modules which are 25x38mm in size and commonly known as floor box modules. The apertures are all placed in a Vertical orientation to allow easier access for cables.


The big advantage of this design is that the box itself allows either of two different grommet holes to save carrying different types

General

Sale Unit	Cardboard Box	
Barcode	5028088015390	
Weight Packed	0.44 Kg	
Dimension Packed	80x70x150mm	
	Height Width Depth	
Dimension loose	70x60x132mm	see drawing below
Commodity Code	Commodity Code	94032080

For Trade and Bulk buyers

Carton Quantity	20
Dimension	38.5x30.5x16.5 cm
NW	10.5 kg
NW	11.5 kg

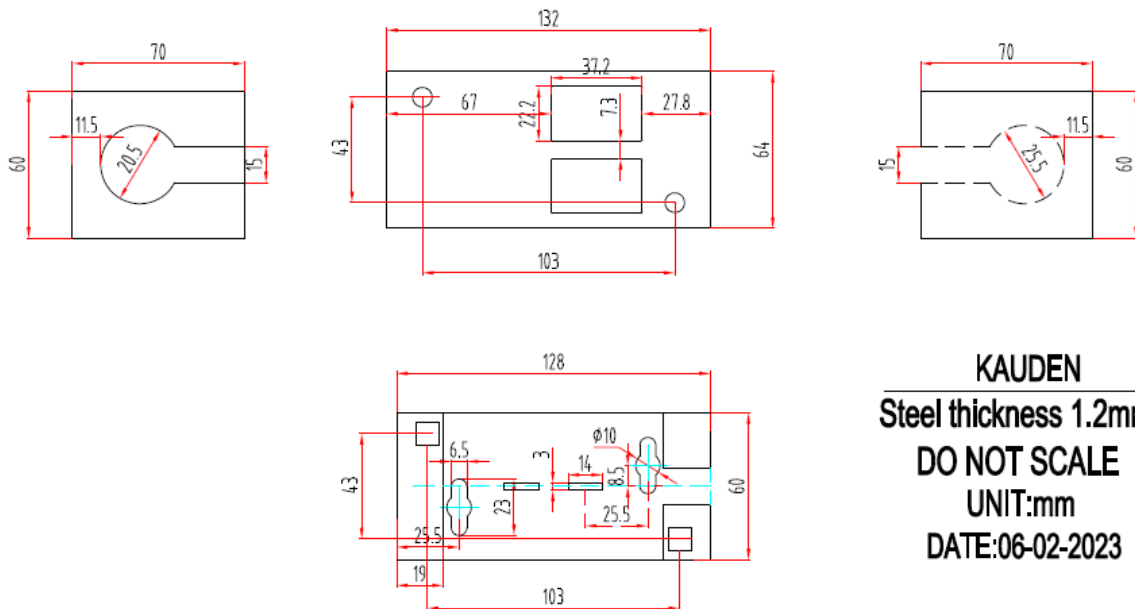

KAUDEN
Steel thickness 1.2mm
DO NOT SCALE
UNIT:mm
DATE:06-02-2023