


243 mm

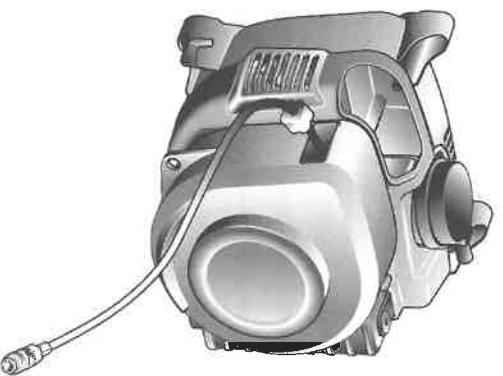

- | | | | |
|----|--------------------------------------|----|----------------------------------|
| IT | Foglio istruzioni di montaggio | SI | Navodila za montažo |
| GB | Assembly instruction sheet | HU | Összeszerelési útmutató |
| FR | Notice d'instruction pour le montage | CZ | Montážní návod |
| DE | Montageanleitung | SK | Montážny návod |
| ES | Foja de instrucciones de montaje | RU | Инструкция по монтажу |
| PT | Folha de instruções de montagem | NO | Blad med monteringsinstrukser |
| NL | Blad met montage-instructies | TR | Montaj talimatları keşidi |
| DK | Instruktionsark | RO | Fişă cu instrucţiuni de montare |
| SE | Monteringsanvisningar | BG | Инструкция за монтаж |
| FI | Asennusohjelehtinen | RS | Brošura sa uputstvima za montažu |
| GR | Φύλλο οδηγίων συναρµολόγησης | LT | Surinkimo instrukcijos lapas |
| PL | Instrukcja montażu | EE | Päigaldusjuhiste leht |
| HR | List s uputama za montiranje | LV | Uzstādīšanas instrukciju lapa |

264 mm
247 mm

IT **Attenzione!** Questo compressore deve essere utilizzato esclusivamente ad una parete solida e non deve essere fissato ad una parete di tipo soffitto. Per il fissaggio sui muri piani o in cemento, utilizzare i tasselli ad espansione. Per il fissaggio su qualsiasi altra superficie (verificando preventivamente che la parete possa reggere il peso del compressore), acquistare viti e tasselli di tipo appropriato.


GB **Warning!** This compressor shall only be used fixed to a wall suitable to support its weight. It is forbidden to use the compressor in any other configuration. For fitting on solid or concrete walls, use screws and expansion plugs. For fitting on any other surface (previously verify that the wall can support the weight of the compressor), purchase appropriate screws and plugs.

- 1**
- (not included)**
- x4**
- x4**
- (included)**




13 mm

236 mm

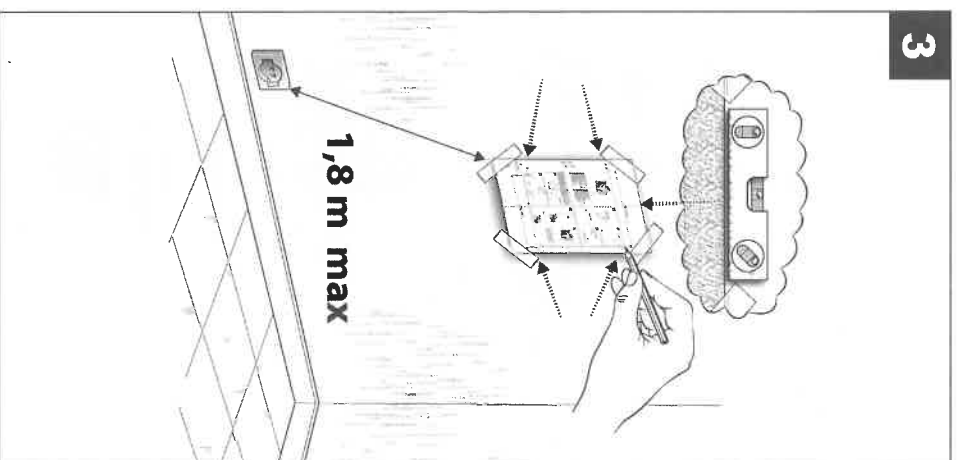


1,8 m max

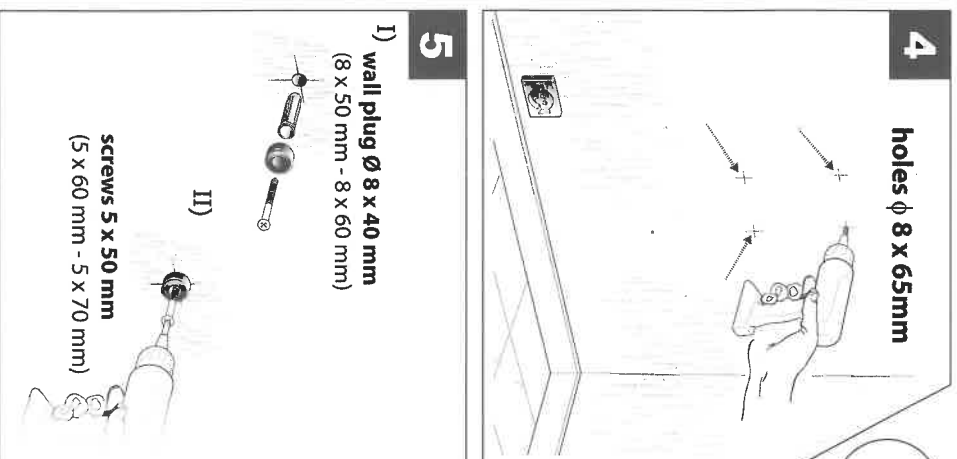

holes ϕ 8 x 65mm

I) wall plug ϕ 8 x 40 mm
(8 x 50 mm - 8 x 60 mm)

screws 5 x 50 mm
(5 x 60 mm - 5 x 70 mm)

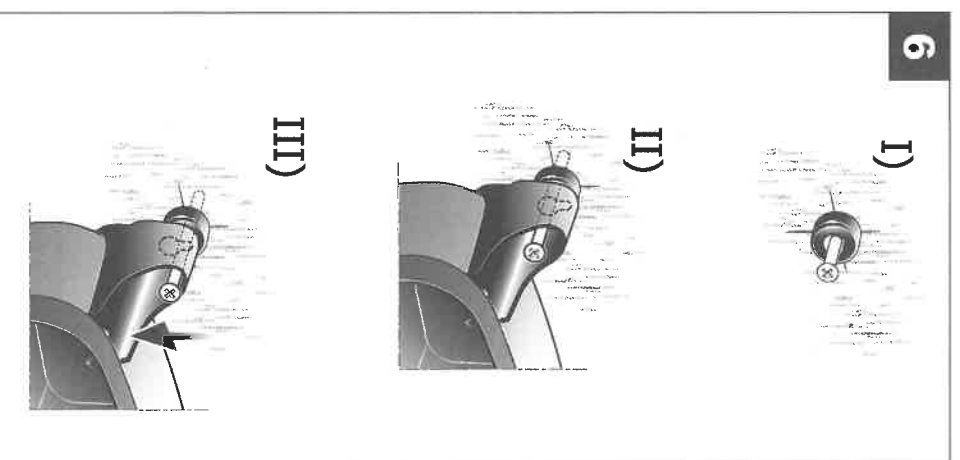

6

7

(IT) Fare riferimento al manuale istruzioni per la descrizione delle figure (riportate su questo foglio istruzioni).

(GB) Refer to the instruction manual for the description of the figures (shown on this instruction sheet).