




PRODUCT SPEC SHEET

SKU 76791

Model:VT-701CL-SN

EAN:3800170217928

VT-701CL-SN CANLESS FIRE RATED GU10 FITTING IP20 SATIN NICKEL BEZEL

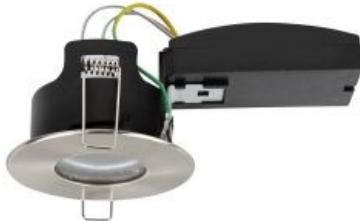

IP20
STANDARD

03
YEAR
WARRANTY

- Twist & lock fire rated canless fitting designed with GU10 base(*lamp not included)
- Fire-rated to resistance of 30,60,90 Mins
- Elegant Black+Satin Nickel color finish
- Easy connection - Quick Connector included
- Insulation Cover available(*not included)
- Spring clips for safer installation and easy maintenance
- IP20 rated protection
- Suitable for residential and commercial installations

TECHNICAL INFORMATION

Cutting Size:	75 mm
Model:	VT-701CL-SN
Installation Type:	Recessed
Input Power:	AC:200-240V, 50Hz
Unit Color:	Black+Satin Nickel
Body Type:	Pressed Steel
Dimension:	91x70mm
Base:	GU10
Shape:	Round
IP Rating:	IP20

LISTING DETAILS

SKU:	76791
Model:	VT-701CL-SN
EAN:	3800170217928
Commodity Code:	9405110000

PACKAGING

Gross Weight (Kgs):	0.24
Unit CBM:	0.001178
Dimension:	91x70mm

MASTER BOX PACKAGING

Box Qty:	100
Qty Per Pallet:	
Length (Box) mm:	120

Width (Box) mm:

105

Height (Box) mm:

85