




Lifemax Professional Humidifier

SKU: 1801

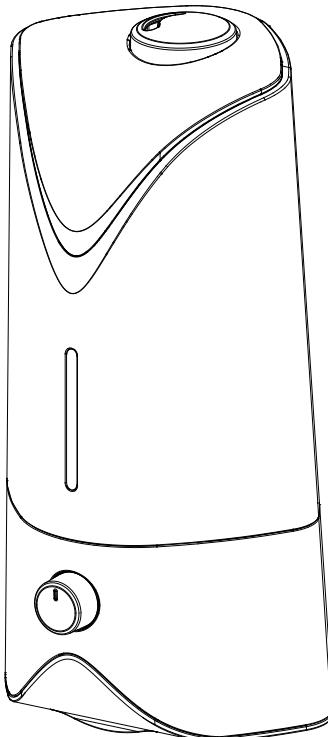

WWW.LIFEMAXUK.CO.UK

Thank you for purchasing the Lifemax Professional Humidifier.

Our Professional Humidifier boasts a high velocity output, pushing particles high into the air to provide enhanced coverage.


The simple rotary control offers continual power adjustment with auto-off feature.

Quiet in operation, this Humidifier is ideal for use in the bedroom for relief from dry air.



INSTRUCTIONS

To fill the tank, start by removing it from the base by lifting it up as shown in the diagram. Turn the tank upside down and remove the tank cap by screwing it off in an anti-clockwise direction. Fill the tank as desired or up to the max level shown on the tank. Do not overfill the tank. Replace the cap by screwing it back onto the tank in a clockwise direction. Ensure the cap has been correctly and securely replaced on the tank, then turn the tank upright and place back onto the base.

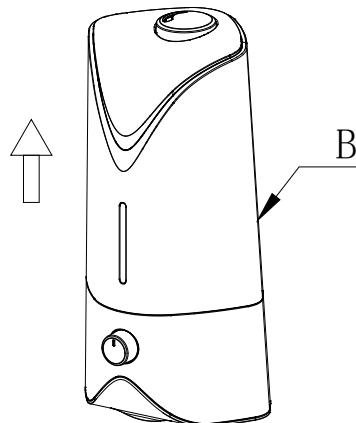

Plug the power into a mains socket. Turn the control knob on the front of the Humidifier in a clockwise direction to commence operation, a blue light on the water level indicator will come on and mist will begin being produced from the top of the Humidifier. To adjust the mist output turn the control knob on the front of the Humidifier to the desired level. To turn the machine off, turn the control knob in an anti-clockwise direction as far as it will go, the blue indicator light will turn off.

Please note that if your Humidifier runs out of water it will stop working until the water tank is refilled.

MAINTENANCE

To ensure your Humidifier continues to work at the best of its capability it is important to clean and maintain it regularly, especially if you are in a hard water area. We recommend using distilled or de-mineralized water as tap water can contain minerals that will create deposits inside your Humidifier and can affect its operation.

Clean the base by removing the water tank and partially filling the cavity with 8-oz undiluted white vinegar (see diagram 1). Leave this solution in the base for 20 minutes. Clean the inside of the tank by half filling it with hot water, add half a cup of white vinegar, then replace the tank cap and shaking vigorously for one minute. Pour the solution away and rinse the tank thoroughly twice. After 20 mins pour away the vinegar solution from the base and gently scrub the area around the transducer and cavities in the base with a soft brush to remove any deposits. Rinse all parts twice with clean warm water.

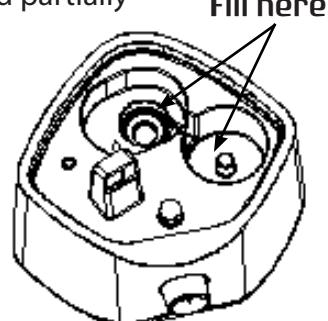


Diagram 1

01635 874323

TECHNICAL SPECIFICATION

Model No: 1801

Rated Max. Moisture Capacity $\geq 180\text{ml/h}$

Water Tank Capacity: 2.6L

Rated Voltage: 100-240v

Rated Frequency: 50/60Hz

Rated Power: 20W

TROUBLESHOOTING

PROBLEM	REASON	SOLUTION
No mist	Not plugged in	Plug into main
	Not powered on	Turn mains on
	No water in tank	Add water
	Overfilled tank	Remove water
Peculiar mist smell	New machine	Remove tank and dry thoroughly. Leave for 12 hours before operating again
	Dirty or old water	Clean the tank and replace the water
Strange noise	Tank not installed correctly	Remove tank and reinstall ensuring correct installation
	No water in tank	Check water level
	Machine on unlevel surface	Place on a flat, level surface
Water in tank but no operation	-	Turn off, remove tank, replace tank and turn back on.

Lifemax Ltd

1 Pipers Court, RG19 4ER

www.lifemaxuk.co.uk

Please retain for reference



WWW.LIFEMAXUK.CO.UK