



SnapBack

Magnetic External SSD



Stick it. Snap it. Back it up.

Meet the Verbatim SnapBack SSD: your ultimate 4K content companion. Film in Apple ProRes at 60fps, snap high-res photos, and never worry about running out of space again.

Built for creators, vloggers, and filmmakers, SnapBack sticks with you—literally. Its MagSafe design keeps it securely attached for a sleek, cable-ready setup. Shoot handheld or on the move without juggling gear.

When it's time to offload, transfer at lightning-fast 20 Gbps with USB 3.2 Gen 2x2. Massive 4K files? Done in seconds, thanks to exFAT preformatting for huge files and cross-platform use with Windows and macOS.

Plus, Nero 3-2-1 backup software keeps your projects safe with automated protection. From set to studio, SnapBack delivers a smooth, stress-free workflow.

This isn't just storage—it's creative freedom in your pocket.



USB 3.2 Gen 2x2
(20 Gbps)



Magnetic
Hold



Supports
4K Video Recording



Two Cables
Included



[verbatim.com](https://www.verbatim.com)

General Information

Approx. product dimensions LxWxH	70 x 8.2 x 62 mm
Product weight	40 g
Case Material	Plastic
Colour	Mocha Metallic / Blue Metallic
Form factor	Squared
USB Port	USB-C
Cable	C to U cable for Phone 6.80cm; C to C cable for PC 20cm
Interface	USB 3.2 Gen 2x2 (max 20 Gbps)
File System	Preformatted in exFAT
Compatibility	Windows, macOS
Warranty	2 year limited warranty

Performance

Capacity	512 GB	1 TB	2 TB
PN	32060	32061 - 32075	32062 - 32076
Max Sequential Read Speed	1900 MB/s	2000 MB/s	2000 MB/s
Max Sequential Write Speed	1800 MB/s	1800 MB/s	1800 MB/s

 

Storage and Operating Conditions

Storage temperature	-20°C to +65°C
Operating temperature	0°C to +40°C
Operating humidity	0% to 90% RH

PN	Description	Tariff Code	Bar Code	EAN128 Code	EAN14 Code
32060	Verbatim SnapBack SSD 512 GB Mocha Metallic	84717098	023942320609	(02)00023942320609(37)04(91)833 (02)00023942320609(37)16(91)833	20023942320603 50023942320604
32061	Verbatim SnapBack SSD 1TB Mocha Metallic	84717098	023942320616	(02)00023942320616(37)04(91)833 (02)00023942320616(37)16(91)833	20023942320610 50023942320611
32075	Verbatim SnapBack SSD 1TB Blue Metallic	84717098	023942320753	(02)00023942320753(37)04(91)833 (02)00023942320753(37)16(91)833	20023942320757 50023942320758
32062	Verbatim SnapBack SSD 2TB Mocha Metallic	84717098	023942320623	(02)00023942320623(37)04(91)833 (02)00023942320623(37)16(91)833	20023942320627 50023942320628
32076	Verbatim SnapBack SSD 2TB Blue Metallic	84717098	023942320760	(02)00023942320760(37)04(91)833 (02)00023942320760(37)16(91)833	20023942320764 50023942320765

Logistic Information

Product Dimensions: L x W x H	70 x 8.2 x 62 mm
Product Weight:	40 g
Units per Pack:	1
Pack Dimensions:	85.5 x 24 x 102.5 mm
Pack Weight:	86 g
Packs per Inner Carton:	4
Inner Carton Dimensions: L x W x H	102 x 91.5 x 132.5 mm
Inner Carton Weight:	442 g
Packs per Outer Carton:	16
Outer Carton Dimensions: L x W x H	213 x 194 x 154.5 mm
Outer Carton Weight:	1934 g
Outer Cartons per Layer:	25
Layers per Pallet:	5
Units per Pallet:	2000

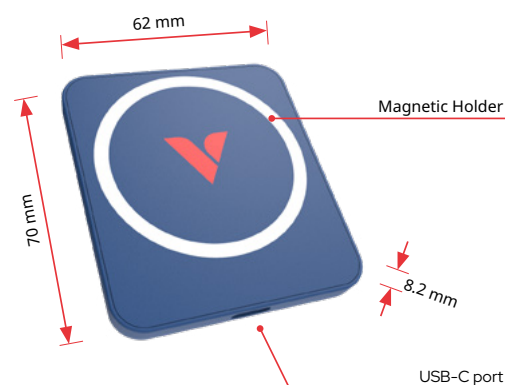

Pack Contents

- Verbatim SnapBack SSD
- USB-C to USB-C cable 20cm
- USB-C to USB-C U shaped cable 6.8cm
- Magnetic ring
- Quick Start Guide
- Preloaded contents:
 - User Manual
 - Nero 3-2-1 Back Up SW*
 - Formatter Software*

* Not compatible with Mac OS



System Requirements

USB connector: USB-C

Interface: USB 3.2 Gen 2x2

OS: Windows 10 or higher
Mac OS 10.14 or higher
iOS 17 or higher

Warranty

2 year limited warranty

For more information, please
contact your key account manager



Publication date: 21-10-2025
© 2025 Verbatim. All rights reserved.
All brand names are registered trademarks of their respective owners.
Unauthorized use strictly prohibited.
Specifications are subject to change without prior notice.

