

PHILIPS



Open-ear true
wireless earbuds

2000 series

True wireless open earbuds

Ear-cuff style

Up to 28 hours play time

Bluetooth multipoint



TAQ2000WT

Ear-cuff style. Open-ear fit.

Enjoy clear audio and all-day comfort with the true wireless open earbuds that you wear like an ear cuff. Each bud clips on lightly but securely, while the open-ear design lets you hear the world as well as what you're listening to.

True wireless open earbuds. Ear-cuff style.

- Ear-cuff style open earbuds. Comfy all day
- Up to 28 hours play time. Slimline charging case
- Stable Bluetooth multipoint connectivity

Responsible design

- Responsible design and packaging
- Plastic-free packaging and soy-based ink
- IPX4 splash and sweat resistant

Your stylish everyday companion

- Clear calls. They'll hear what you're saying
- Customizable on-ear controls
- Philips Headphones app. Personalize your earbuds


2000 series

Open-ear true wireless earbuds

TAQ2000WT/97

Highlights

Ear-cuff style open earbuds

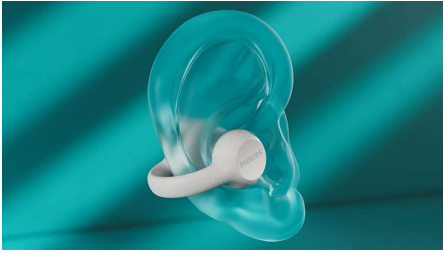

These open earbuds clip on lightly but securely to your outer ear and a flexible joint lets you adjust the grip for maximum comfort. Precision air-conduction drivers direct sound into your ear canal without sealing it, so you'll hear what's going on in your immediate surroundings too.

28 hrs play time (7 + 21)



You get 7 hours play time from a full charge, and an extra 21 hours from the case. If you need a quick boost, pop the earbuds back in the case for 15 minutes to get an extra hour. It takes 2 hours

to recharge the earbuds fully, and mono mode lets you use one earbud at a time while the other one charges.

Bluetooth 5.4 multipoint



Advanced Bluetooth connectivity gives you a more stable connection for seamless streaming, and you can connect to two Bluetooth devices at the same time. Enjoy that playlist or listen uninterrupted to your favorite podcast without annoying dips in the sound.

Responsible design

We're continually working to make our supply chain more sustainable and transparent. Our plastic-free packaging uses FSC-certified recycled cardboard and soy-based ink.

IPX4 splash/sweat resistant

With their featherlight design, comfortable fit, and an IPX4 rating, these true wireless open earbuds are ready for everyday use. Fully splash

resistant, they won't mind a little sweat and you don't need to worry about getting caught in the rain.

Clear calls

Your voice will come through clearly when you're on a call. A dedicated mic picks up the sound of your voice while a noise-reduction algorithm quietens some of the background noise from the world around you.

On-ear controls

There are handy button controls on the earbuds for playback, volume, and calls. Prefer to use the left or right earbud? You can customize how these controls are set up via the Philips Headphones companion app.

Philips Headphones app

As well as customizing the on-ear controls, you can use our companion app to activate Dynamic Bass, get the latest firmware updates, manage connected devices, and even listen to in-app soundscapes. There are soundscapes that you can play together with binaural beats to aid focus, relaxation, or sleep. Or try the ambient and nature soundscapes.

2000 series

Open-ear true wireless earbuds

TAQ2000WT/97

Specifications

Sound

Frequency range: 100 - 20,000 Hz
Speaker diameter: 12 mm
Impedance: 16 Ohm
Maximum power input: 20 mW
Sensitivity: 113 dB (1K Hz, 1mW)
Driver type: Dynamic

Connectivity

Bluetooth version: 5.4
Bluetooth profiles: HFP, A2DP, AVRCP
Maximum range: Up to 10 m
Multipoint connection
Supported codec: SBC

Outer Carton

Length: 23.90 cm
Number of consumer packagings: 24
Width: 22.80 cm
Gross weight: 2.785 kg
Height: 20.00 cm
GTIN: 1 48 95229 16641 4
Nett weight: 1.44 kg
Tare weight: 1.345 kg

Convenience

Water resistance: IPX4
Philips Headphones app support
Mono mode for TWS
Firmware updates possible
Type of controls: Button

Inner Carton

Length: 11.10 cm
Number of consumer packagings: 3
Width: 10.40 cm
Height: 8.50 cm
Nett weight: 0.18 kg
Gross weight: 0.315 kg
Tare weight: 0.11 kg
GTIN: 2 48 95229 16641 1

Power

Number of batteries: 3 pcs
Music play time: 7 + 21 hour(s)
Charging time: 2 hour(s)
Fast charging time: 15 mins for 1 hour
Battery type(Charging case): Lithium Polymer (built-in)
Battery type(Earbud): Lithium Polymer (built-in)
Battery weight (Total): 11.2 g
Battery capacity(Case): 450 mAh
Battery capacity(Earbud): 51 mAh

Packaging dimensions

Height: 9.60 cm
Packaging type: Carton
Type of shelf placement: Hanging
Width: 9.65 cm
Depth: 3.40 cm
Number of products included: 1
EAN: 48 95229 16641 7

Gross weight: 0.085 kg
Nett weight: 0.060 kg
Tare weight: 0.025 kg

Accessories

Quick Start Guide
Charging case

Design

Color: White
Wearing style: Ear-clip
Ear fitting: Open-ear
In-ear fitting type: Open fit

Telecommunication

Microphone for call: 1 mic

Dimensions

Charging case dimension(WxDxH): 6.55 x 2.77 x 3.92 cm
Earbud dimension(WxDxH): 2.60 x 2.70 x 1.95 cm
Total weight: 0.048 kg

Voice assistant

Voice assistant compatible: Apple Siri, Google Assistant
Voice assistant activation: Multi-Function touch
Voice assistant support

