


PXF4050AAC Datasheet

Product Name // 25 M, Single Mode, Cabled, Flex fiber connector

 [View Product Page](#)

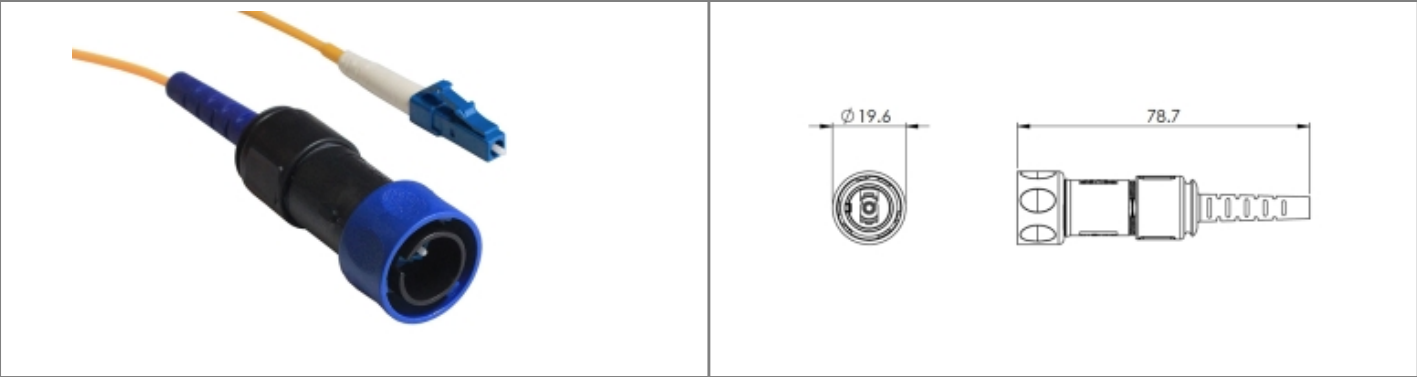

// Product Description:	
- Flex Fiber Connector to LC type Connector - Sealed to IP66, IP68, IP69K when mated with compatible connector - no cable options, or pre-terminated from 5M - 450M available - Simplex LC type fiber connector	- Choices of OS1, OM1 and OM3 cables for single or multimode - PXP4081 Sealing Cap available separately to maintain IP rating of unmated connectors - Mate with Inline fiber connector or panel mount connectors PXF4051, PXF4053

// General Information:	
Product Display Title:	Flex Fiber Connector to LC type Connector
Product Family:	Circular Fiber Connectors
Product Series:	4000 Series - Simplex LC Fiber Buccaneer
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Contact Type:	LC Fiber
Coupling Type:	30 Degree coupling
Diameter Over Coupling Ring Mm:	19.7mm
Fibre Mode:	OS1
Flamability Rating:	UL94V-0
Function:	Flex to LC Connector Double Ended Fiber Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C

// Product PDF Links

 4000 Series Fiber connectors...

// Product 3D CAD Model Links

 PXF4050AAC3D CAD Model