



Part Number : [1201080558](#)


Product Description : Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 24 AWG, Teal Unshielded TPE Cable, 2.0m (6.56') Length, 6.10mm (.240") Diameter

Series Number : 84702

Status : Active

Product Category : Circular Industrial Cordsets

Engineering Part Number : E66A06004M020

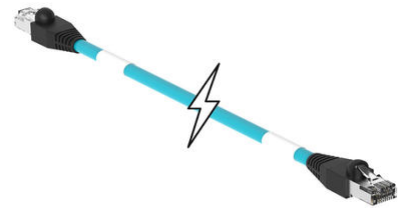

Documents and Resources

Drawings

[1201080558_sd.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	 per SJ/T 11365-2006
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2025)4165-DC (25 June 2025)
EU RoHS	Compliant per EU 2015/863

Compliance Statements

- EU RoHS
- REACH SVHC
- Low-Halogen

Industry Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474

- chemSHERPA (xml)

Substances of Interest

- PFAS

EU RoHS Certificate of Compliance

Additional Product Compliance Information

UKCA - Declaration of Conformity

CE - Declaration of Conformity

Part Details

General

Status	Active
Category	Circular Industrial Cordsets
Series	84702
Description	Double-Ended RJ-45 Cordset, 4 Poles, Male (Straight) to Male (Straight), 24 AWG, Teal Unshielded TPE Cable, 2.0m (6.56') Length, 6.10mm (.240") Diameter
IP Rating	IP20
Performance Category	5e
Product Name	Industrial Ethernet
Type	Double Ended
UPC	78172547761

Agency

UL	E361772
----	---------

Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC / 60V DC

Physical

Cable Diameter	6.10mm (.240")
Cable Length	2.0m (6.56')
Color - Cable Jacket	Teal

Connector End A	RJ-45 (standard)
Connector End B	RJ-45 (standard)
Coupling Style	Push and Latch
Gender	Male-Male
Keyway	None
LED Indicator	None
Material - Cable Jacket	TPE
Material - Connector Body	Polycarbonate
Material - Contact	Phosphor Bronze
Material - Coupling Nut	N/A
Material - Plating Mating	Gold
Net Weight	245.000/g
Orientation	Straight to Straight
Poles	4
Temperature Range - Operating	-20° to +75°C
Wire/Cable Type	Unshielded TPE/AWM 2463
Wire Size (AWG)	24