




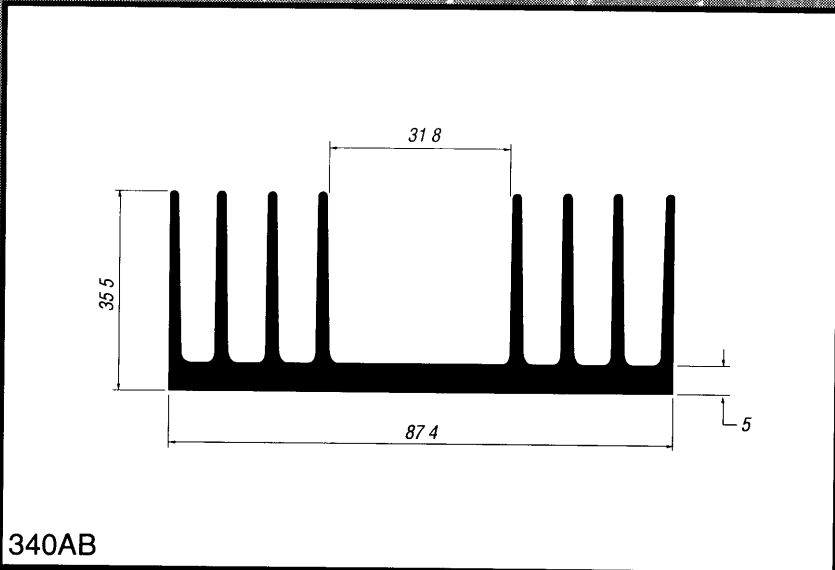



300 SERIES

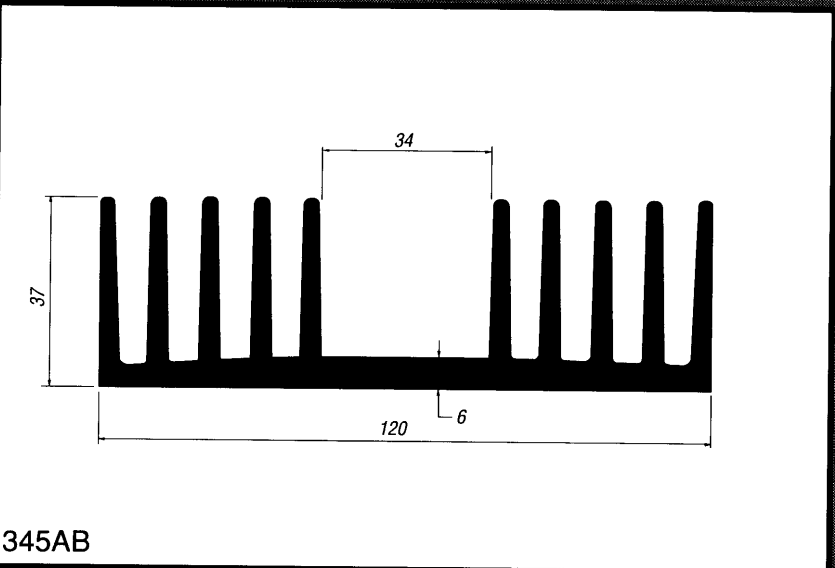

Typical Performance		°k/w Black				
Length		50	75	100	150	200
°k/w		2.40	1.92	1.68	1.45	1.35

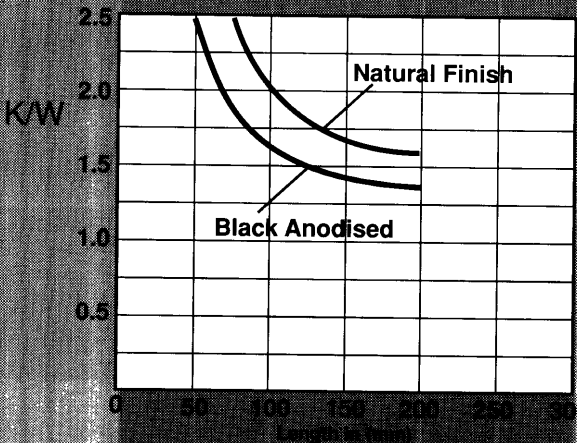

Typical Performance		°k/w Black				
Length		50	75	100	150	200
°k/w		1.50	1.20	1.00	0.85	0.80

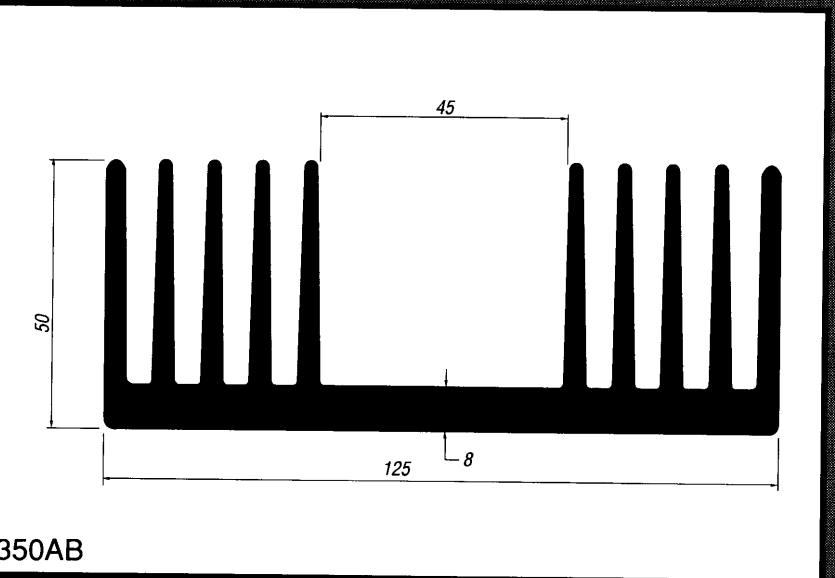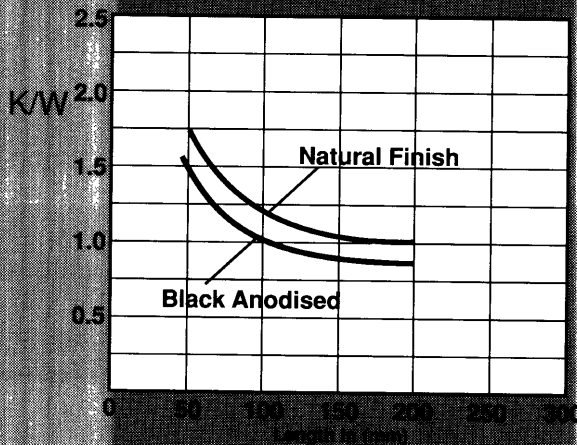

Typical Performance		°k/w Black				
Length		50	75	100	150	200
°k/w		1.20	0.83	0.67	0.50	0.42

