



HD 1110

PLASTIC HORN SPEAKER WITH DRIVER



Description Extremely compact horn speaker with high acoustic output. The HD 1110 is particularly suitable for use in call or alarm systems in places with a high level of background noise. Fully protected against atmospheric agents, it can also be used outdoors.

- Features**
- › Plastic body, GREY RAL 7035
 - › Solid and compact construction
 - › Mounting bracket included
 - › Driver impedance 8 Ohm


Part Number 13133030 HD 1110 8ohm EAN 8024530010140



HD 1110

PLASTIC HORN SPEAKER WITH DRIVER

Line Art 2D

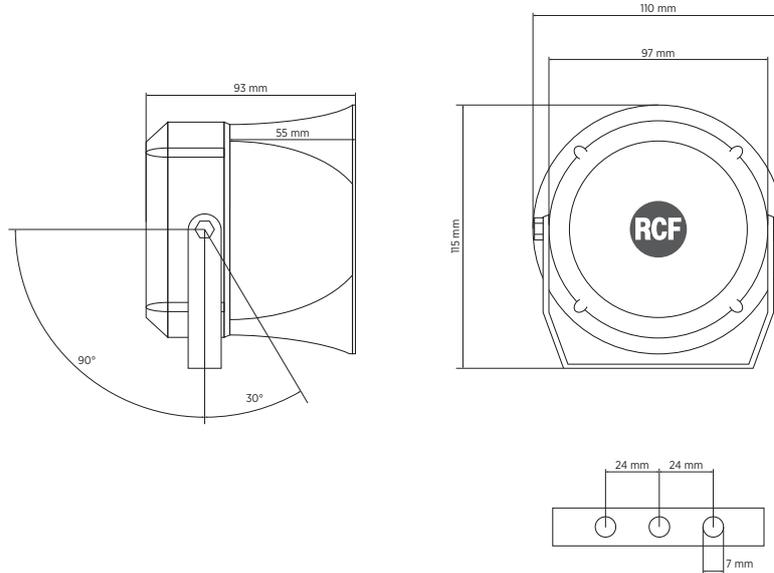

TECHNICAL SPECIFICATIONS

Acoustical specifications	Frequency Response (-10dB)	900 Hz - 13000 Hz
	Max SPL @ 1m	114 dB
	Coverage angle	175°
	System Sensitivity	101 dB
Power section	Nominal Impedance	8 ohm
	Power Handling	20 W
	Peak Power Handling	80 W PEAK
Transducers	Compression Driver	1 x 1.5"
Input/Output section	Input connectors	Cable
	Output connectors	Cable
Standard compliance	Safety agency	CE compliant
Physical specifications	Cabinet/Case Material	Plastic
	Hardware	U bracket
Size / Weight	Depth	93 mm / 3.66 inches
	Diameter	100 mm / 3.94 inches
	Weight	0.42 kg / 0.93 lbs