


## PRODUCT SPECIFICATION SHEET

KB238 Wireless Multimedia UK Layout Keyboard & 5 Button Optical Mouse - Silver With Black Keys

Ref: 24-0238 | Brand: **connektgear**

---

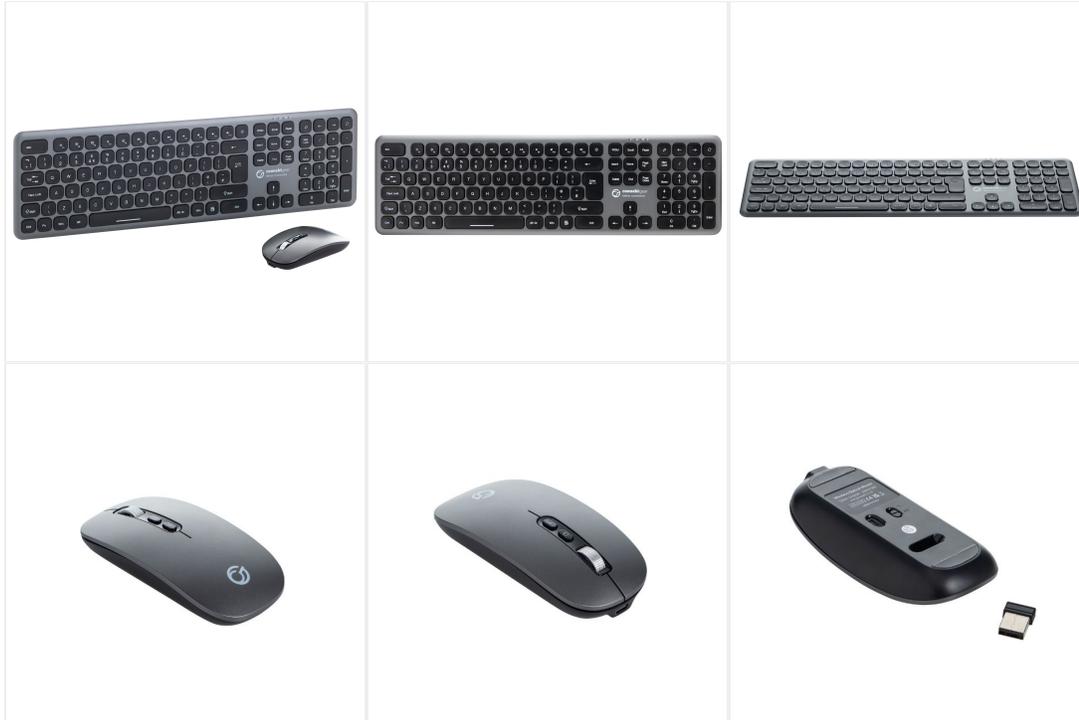

### DESCRIPTION

Our wireless multimedia keyboard and mouse set naturally enhances your workspace, combining a sleek silver design with contrasting black keys for a modern look that suites both home and office setups. With reliable wireless connectivity, simple plug and play setup, and long lasting performance, the KB238 combo is a practical and stylish solution for everyday computing.

The full-size UK layout keyboard features low profile keys for quiet, responsive typing, along with dedicated multimedia shortcut keys that let you control music, volume, and playback at the touch of a button. Its slim design helps reduce desk clutter while maintaining a familiar, comfortable typing experience.

Paired with the keyboard is a wireless 5 button optical mouse, offering smooth tracking, precise control, and added navigation buttons for improved productivity. The ergonomic shape fits naturally in the hand, making it ideal for long working sessions.

### PRODUCT DETAILS

- **KEYBOARD**
- Plug & play set up
- UK layout
- Silk printed keys
- Sturdy & durable construction
- Two year warranty
- **MOUSE**
- Plug & play set up
- 5 Button mouse
- Symmetrical design
- Pre-paired USB nano receiver in the base
- Sturdy & durable construction
- Two year warranty

## INCLUDED COMPONENTS

### TECHNICAL SPECIFICATIONS

- **KEYBOARD**
  - Interface: 2.4G USB Wireless connectivity
  - Keys: 111 (silk printed)
  - MTBF: Button life 3 million cycles
  - LED Indicators: Num, Caps, 2.4G, Charging
  - Dimensions: 444 x 126 x 22mm
  - Working time: Up to 100h
  - Working distance: Up to 10m
  - USB Type C charging port
  - Battery: 500mAh
  - System compatibility: Windows, Mac & Android (OTG adapter required for Android)
- **MOUSE**
  - Interface: 2.4G USB Wireless connectivity
  - Buttons: 5
  - Resolution: 800/1200/1600dpi
  - MTBF: Button life 3 million cycles
  - Dimensions: 107 x 62 x 37mm
  - Working time: Up to 50h
  - Working distance: Up to 10m
  - USB Type C charging port
  - System compatibility: Windows, Mac & Android (OTG adapter required for Android)

### LOGISTICS INFORMATION

Quantity0

Pack TypeBox

Dimensions520(W) x 130(H) x 30(D)mm

MaterialCardboard

Weight0.80kg

Gross Weight0.0000kg

Barcode5035624068469

Country

Commodity0