


## ***miniMEDIA* 12 port 10" Contractor Grade Category 6 patch panel**

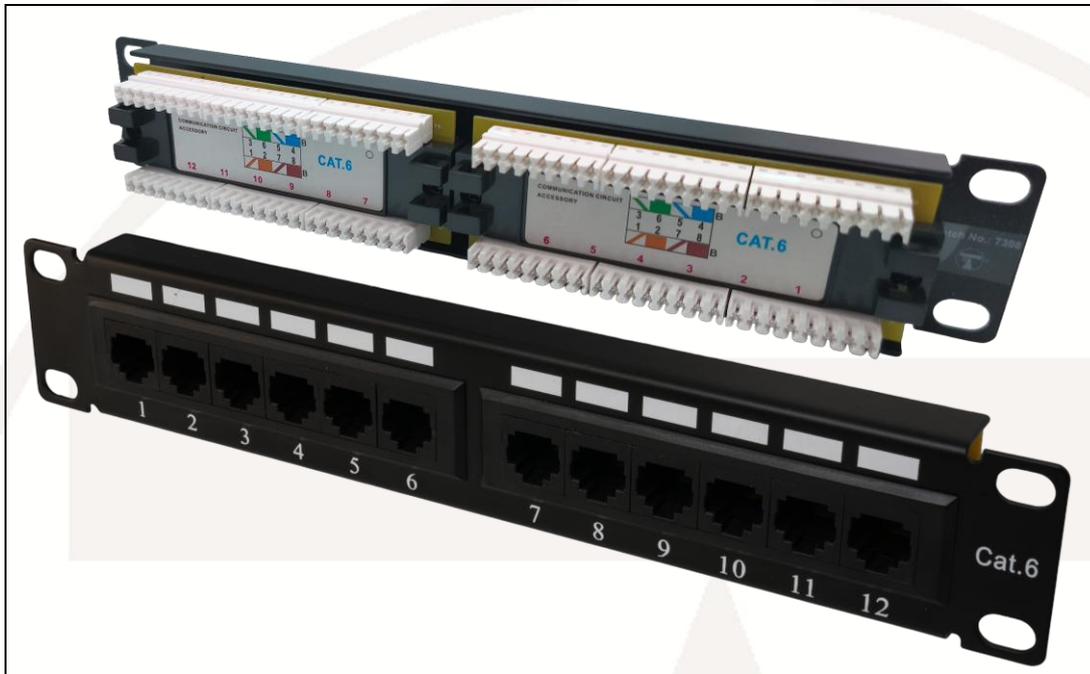

### **10" 12port Contractor Grade Category 6 patch panel (SF12kd)**

***miniMEDIA*** Category 6 10" 12 port UTP contractor grade PCB based patch panel

#### **Features**

- Performs to Category 6 permanent link level
- Accommodates LSA+ type termination tools
- Supplied with cage nut kit and 4 long and 12 short cable ties
- Printed with numbered ports
- Straightforward T568B rear labelling
- Suitable for use with POE

#### **Specifications**

- Weight: 354g (including primary packaging)
- Dimensions: 185x80x60mm (in primary packaging)
- Colour: Black
- Materials: Frame – powder coated 1.5mm cold rolled steel  
Housing – ABS  
PCB – FR-4
- Contacts: Socket – 15µ"/0.381µm gold over nickel over phosphor bronze  
IDC – Nickel plated phosphor bronze

- Durability – Jack: 250 insertion cycles, IDC: 100 insertions
- Suitable for cores 22-26 AWG
- Operating temperature 0<sup>0</sup> to 70<sup>0</sup> C

**Packaging:** Packed in white cardboard box then in cartons of 25

**EAN:** 5055386513786

**Commodity Code:** 85444920

**Country of Origin:** China

ROHS Compliant

Code: SF12kd

