


ORBIT CCT

ULTRA-SLIM CCT SELECTABLE CIRCULAR DOWNLIGHTS

Orbit CCT recessed die cast aluminium circular downlights are available in outputs from 500lm to 1720lm with selectable colour temperatures 3000K / 4000K / 6000K. Featuring an ultra-slim profile of 15mm, Orbit is highly suited to projects where cost is a prime consideration.

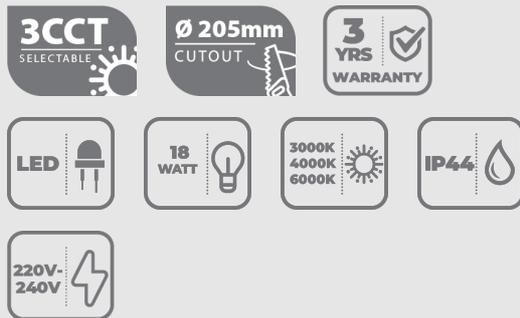

Features

- Ultra slim downlight and driver
- Colour Selectable 3000K | 4000K | 6000K
- Die-cast aluminium body and TP(b) diffuser
- Dimmable drivers available

Specification

Code	Description	Lumen Output	Emergency Lumen Output	Wattage	Efficacy
ORB18-CCT	Orbit Circular Downlight 18W 3CCT 3/4/6K	1550lm		18W	86 lm/W

Product Information

Warranty	3 Years
Colour Appearance (CCT)	3000K 4000K 6000K
IP Rating	IP44 (from below ceiling)
IK Rating	IK04
Voltage	220-240V
Material (Body/Housing)	Die-Cast Aluminium
Material (Diffuser/Cover)	TP(b) Styrene
Colour Rendition (CRI)	Ra >80

Colour Finish	White RAL9003
LED Life Expectancy	L70B50 97,000 Hours
Power Factor	>0.9
Frequency	50/60Hz
Driver Type	Fixed Output
Approval	UKCA CE
Electrical Class	Class II
Working Temperature	-10°C to 50°C



ORBIT CCT

ULTRA-SLIM CCT SELECTABLE CIRCULAR DOWNLIGHTS

Packaging Information

Dimensions (mm)	Ø: 220 x D: 15 mm
Barcode	5055807627313
Box Dimensions (mm)	L: 255 x W: 223 x D: 31 mm
Units/Outer Carton	20

Outer Carton Barcode	15055807627310
Outer Carton Dimensions (mm)	L: 525 x W: 330 x D: 243 mm

