

Samsung U8000F UE43U8092F 109.2 cm (43") 4K Ultra HD Smart TV Wi-Fi Black


Brand : Samsung

Product family: U8000F

Product code:
UE43U8092F


Product name : UE43U8092F

Samsung U8000F UE43U8092F. Display diagonal: 109.2 cm (43"), Display resolution: 3840 x 2160 pixels, HD type: 4K Ultra HD, Display technology: LED, Screen shape: Flat. Smart TV. Motion interpolation technology: Motion Xcelerator, Native aspect ratio: 16:9. Digital signal format system: DVB-C, DVB-S2, DVB-T2. Wi-Fi, Ethernet LAN. Product colour: Black

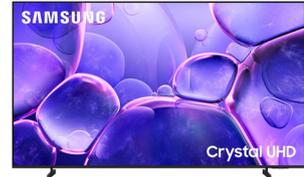

Display		Performance	
Display diagonal *	109.2 cm (43")	SmartThings app support	✓
HD type *	4K Ultra HD	DVD player	✗
Display technology *	LED	Ports & interfaces	
Screen shape *	Flat	Audio Return Channel (ARC)	✓
Native aspect ratio *	16:9	PC in (D-Sub) *	✗
Supported video modes	2160p	Ethernet LAN (RJ-45) ports	1
Supported graphics resolutions	3840 x 2160	USB 2.0 ports quantity *	1
Automatic brightness control	✓	RF ports quantity	1
Motion interpolation technology *	Motion Xcelerator	Common interface (CI) *	✓
Native refresh rate	50 Hz	Common interface Plus (CI+) *	✓
Display resolution *	3840 x 2160 pixels	Common interface Plus (CI+) version	1.4
Display diagonal (metric)	108 cm	HDMI ports quantity *	3
TV tuner		Consumer Electronics Control (CEC)	Anynet+
Tuner type *	Analog & digital	Management features	
Digital signal format system *	DVB-C, DVB-S2, DVB-T2	Control type	Remote
Smart TV		Voice guide	✓
Smart TV *	✓	Electronic Programme Guide (EPG)	✓
Internet TV *	✓	On Screen Display (OSD)	✓
Operating system installed *	Tizen	Number of OSD languages	27
Apple AirPlay 2 support	✓	On Screen Display (OSD) languages	Multi
Sound mirroring	✓	Auto power off	✓
Hybrid Broadcast Broadband TV (HbbTV)	✓	Works with Samsung Bixby	✓
Hybrid Broadcast Broadband TV (HbbTV) version	2.0.4	Power	
Audio		Power consumption (typical) *	52 W
RMS rated power *	20 W	Power consumption (standby) *	0.5 W
Audio output channels	2.0 channels	Power consumption (max)	110 W
Audio pre-selection descriptor	✓	Energy efficiency class (SDR) *	G
Adaptive sound	✓	Energy efficiency class (HDR) *	G
Object Tracking Sound+ (OTS+)	✓	Energy consumption (SDR) per 1000 hours *	52 kWh
Enhanced Audio Return Channel (eARC)	✓	Energy consumption (HDR) per 1000 hours *	102 kWh
		AC input voltage	220 - 240 V

Network		Power	
Wi-Fi *	✓	AC input frequency	50/60 Hz
Wi-Fi standards	Wi-Fi 5 (802.11ac)	Energy saving mode	✓
Bluetooth *	✓	Energy efficiency scale	A to G
Bluetooth version	5.3	Brand-specific features	
Ethernet LAN *	✓	Samsung technologies (AV/TV)	4K Upscaling, Q-Symphony, Samsung Knox
Web browser	✓		
Design		Weight & dimensions	
Product colour *	Black	Width (with stand)	957.8 mm
VESA mounting *	✓	Depth (with stand)	157 mm
Panel mounting interface	200 x 200 mm	Height (with stand)	609 mm
Introduction year	2025	Weight (with stand)	6.6 kg
Bezel type	3 Bezel-less	Width (without stand)	957.8 mm
Slim fit wall mount support	✓	Depth (without stand)	76.3 mm
Stand type	Legs stand	Height (without stand)	558.8 mm
Stand colour	Black	Weight (without stand)	6.4 kg
Performance		Stand width	61.3 cm
High Dynamic Range (HDR) technology	Filmmaker Mode, High Dynamic Range 10 (HDR10)	Stand depth	15.7 cm
Eco sensor	✓	Packaging data	
AI Upscale	✓	Manual	✓
TV key support	✓	Package width	1065 mm
Backlight dimming technology	UHD Dimming	Package depth	118 mm
Picture processing technology	Samsung Contrast Enhancer, Samsung Mega Contrast	Package height	635 mm
High Dynamic Range (HDR) supported *	✓	Package weight	9 kg
Game features	Auto Low Latency Mode (ALLM), HGIG, Variable Refresh Rate (VRR)	Packaging content	
Plug and Play	✓	Cables included	AC
		Remote control included	✓
		Remote control type	TM2240A
		Other features	
		Annual energy consumption	151 kWh

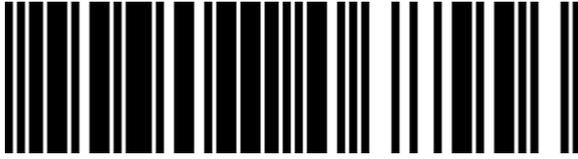

8806097068556

Catalog Object Cloud



Disclaimer. The information published here (the "Information") is based on sources that can be considered reliable, typically the manufacturer, but this Information is provided "AS IS" and without guarantee of correctness or completeness. The Information is only indicative and can be changed at any time without notification. No rights can be based on the Information. Suppliers or aggregators of this Information do not accept any liability with regard to the content of (web)pages and other documents, including its Information. The publisher of the Information can not be held liable for the content of 3rd party websites that are linking this Information or are linked to from this Information. You as the User of the Information are solely responsible for the choice and usage of this Information. You are not entitled to transfer, copy or otherwise multiply or distribute the Information. You are obliged to follow the directions of the copyright owner(s) with regard to the use of the Information. Exclusively Dutch law is applicable. With regard to price and stock data on the site, the publisher followed a number of starting points, which are not necessarily relevant for your private or business circumstances. Therefore, the price and stock data are only indicative and are subject to changes. You are personally responsible for the way you use and apply this information. As a user of the Information or sites or documents in which this Information is included, you will adhere to standard fair use including avoidance of spamming, ripping, intellectual-property violations, privacy violations, and any other illegal activity.