



# CLIFF

## METAL 4 PIN XLR SOCKETS (FEEDTHROUGH STYLE)

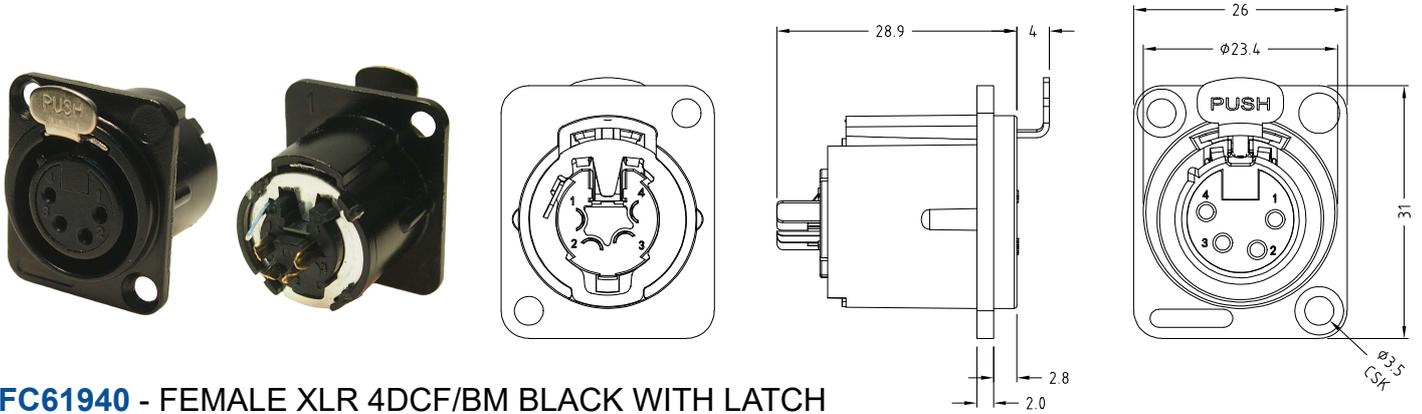

**FC61940** - FEMALE XLR 4DCF/BM BLACK WITH LATCH

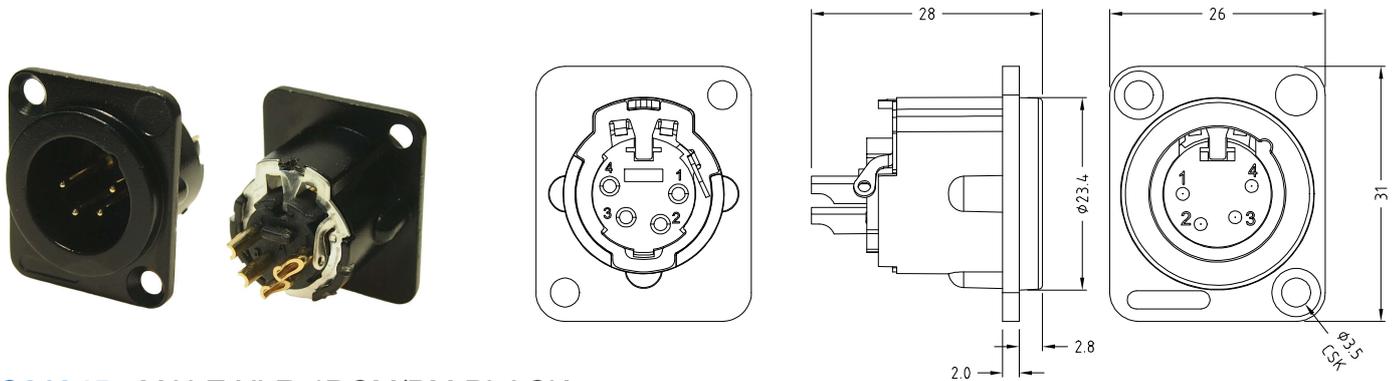

**FC61945** - MALE XLR 4DCM/BM BLACK

### SPECIFICATION

Contact Resistance:  $\leq 7\text{m}\Omega$

Insulation Resistance:  $\geq 5000\text{M}\Omega$

Withstand Voltage: 1400V

Durability (Mating / Unmating):  $\geq 2000$  insertions

Insertion and Extraction force: 10-80N

These metal 4 pin XLR's can be fitted into our 1U racks.

