

# Expression Premium XP-7100



The XP-7100 is an affordable, compact and easy-to-use A4 printer that produces clear and vibrant double-sided prints with wireless printing options, an automatic document feeder to scan and copy multiple documents and with a 10.9cm interactive touchscreen.

This stylish, top-of-the-range, compact all-in-one is ideal for busy households who want to print outstanding glossy photos and crisp, clear documents. Wi-Fi connectivity and mobile printing offer great flexibility, while features such as A4 double-sided printing, an Automatic Document Feeder (ADF) and a 10.9cm touchscreen help make this device quick and easy to use.

## Stylish and versatile

Unsung tech is a thing of the past; this all-in-one looks great from every angle. It features an Automatic Document Feeder for scanning and copying single or double-sided multi-page documents, dual paper trays for A4 and photo media, double-sided A4 printing to save paper and a rear speciality paper feed for printing on thicker media.

## Best of both worlds

Enjoy the beauty of high-quality photos and crisp, clear text documents with the five-colour Claria Premium dye and pigment ink set. Photos are crystal clear with vibrant colours and deep, rich blacks as Claria Premium incorporates a photo black ink cartridge.

## Mobile printing

Print using smart devices with Epson's free apps, Wi-Fi, and Wi-Fi Direct. Print and scan wirelessly with Epson's iPrint\* app or try Epson's Creative Print\* app to print photos from Facebook, create greeting cards and more. And print from almost anywhere in the world by emailing files to the printer with Epson Email Print\*.


## Fuss-free features

There's a 10.9cm interactive touchscreen and a memory card slot for easy navigation and printing photos directly without a computer. It's also possible to print on suitable CDs and DVDs. For even easier operation, a motorised control panel and output tray mean hassle-free printing.



## KEY FEATURES

- Compact and versatile A4 multifunction printer with easy-to-use touchscreen & automatic document feeder**  
 High-quality print, copy and scan in one machine
- Wireless connectivity lets you print from anywhere**  
 Print easily from your smartphone or tablet using the Epson iPrint and Creative Print apps, where you can use your photos to create and print photo books, greetings cards and more\*
- Save money by only replacing the colour used**  
 With Epson's genuine individual inks
- Money and paper saving double-sided printing**  
 Automatically print on both sides to reduce paper usage and save money
- User-friendly and versatile paper trays**  
 Front-loading paper trays for A4 paper and photo sized. Plus rear speciality media feed for thicker card and a motorised output tray.
- Legal Statement**  
 Complies with The UK Product Security and Telecommunications Infrastructure (Product Security) requirements. Epson will provide security updates for 7 years from purchase

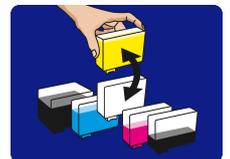

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	360 Nozzles Black, 180 Nozzles per Color
Minimum Droplet Size	1.5 pl, With Variable-Sized Droplet Technology
Ink Technology	Claria™ Premium Ink
Printing Resolution	5,760 x 1,440 DPI
Category	Home, Photo
All-in-One Functions	Print, Scan, Copy

### PRINT

Printing Speed ISO/IEC 24734	15.8 pages/min Monochrome, 11 pages/min Colour
Maximum Printing Speed	12 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper), 32 pages/min Colour (plain paper 75 g/m <sup>2</sup> ), 32 pages/min Monochrome (plain paper 75 g/m <sup>2</sup> )
Colours	Black, Photo Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

### SCAN

Optical Resolution	1,200 DPI x 4,800 DPI (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

### PAPER / MEDIA HANDLING

Number of paper trays	2
Paper Formats	Legal, 16:9, 13 x 18 cm, 10 x 15 cm, Letter, No. 10 (Envelope), DL (Envelope), C6 (Envelope), B5, A6 (10.5x14.8 cm), A5 (14.8x21.0 cm), A4 (21.0x29.7 cm), User defined
Duplex	Yes (A4, plain paper)
Print Margin	0 mm top, 0 mm right, 0 mm bottom, 0 mm left (Wherever margin is defined. Otherwise 3mm top, left, right, bottom.)
Automatic Document Feed	30 pages
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets
Rear paper path (special media)	Yes
Motorised Output Tray	Yes
Media Handling	Auto Sheet Feeder, Automatic duplex (A4, plain paper), Borderless Print, CD/DVD print, Rear specialty media feed

### GENERAL

Energy Use	8.7 Watt (Ready), 0.4 Watt (Power off), 16 Watt (standalone copying, ISO/IEC 24712 pattern), 1.2 Watt (sleep mode)
Supply Voltage	AC 220 V - 240 V, 50 Hz - 60 Hz
Product dimensions	390 x 339 x 183 mm (Width x Depth x Height)
Product weight	8.2 kg
Noise Level	4.9 B (A) with Epson Premium Glossy Photo Paper / Photo RPM mode - 36 dB (A) with Epson Premium Glossy Photo Paper / Photo RPM mode
Compatible Operating Systems	Mac OS X 10.6.8 or later, Windows 10, Windows 11, Windows 7, Windows 8, Windows 8.1, Windows Vista, Windows XP SP3, XP Professional x64 Edition SP2
Included Software	Epson Easy Photo Print, Epson Print CD, Epson Scan
Interfaces	USB, Ethernet, WiFi, Wi-Fi Direct, USB host, SD Card Slot
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES)
Mobile and Cloud printing services	Apple AirPrint, Epson Connect (iPrint App, Creative Print App, Email Print, Remote Print Driver, Scan-to-Cloud)
Colour	Black

### OTHER FEATURES

Panel	Type: Color, Touchscreen, Diagonal:10.9 cm
Memory Cards	SDXC, SDHC, SD, MiniSDHC*, MiniSD*, MicroSDXC*, MicroSDHC*, MicroSD* (* Adaptor required, not supplied in box)
Features	Touchscreen, PictBridge, Red eye removal, Photo Enhance, Direct print from USB

## Expression Premium XP-7100

### WHAT'S IN THE BOX

- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges
- Warranty document

## PRODUCT SPECIFICATIONS

---

### PRODUCT SAFETY

Product Safety Warnings      Contains 1,2-benzisothiazol-3(2H)-one. May produce an allergic reaction.  
Contains 2,4,7,9-tetramethyldec-5-yne-4,7-diol. May produce an allergic reaction.  
Always follow the information on the product label.

### OTHER

Warranty      12 months Carry in  
Optional warranty extension available

---

## Expression Premium XP-7100

---

### WHAT'S IN THE BOX

---

- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges
- Warranty document

## LOGISTICS INFORMATION

SKU	C11CH03401
EAN code	8715946651859
Country of Origin	Indonesia
Layer	2 Units
Layer Block	4 Units

For more information please contact:

Home users: 0343 90 37766  
Business users\*: 0871 42 37766  
Republic of Ireland: 01 436 7742  
Or visit us at <https://www.epson.co.uk/contactus>  
\* 10p per minute plus network extras.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

1. see [epson.co.uk/cartridgefootnotes](http://epson.co.uk/cartridgefootnotes)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.  
Product information is subject to change without prior notice.  
Last extracted: 2025-10-06

**EPSON**<sup>®</sup>