

# WorkForce Pro WF-3820DWF Printer



The WF-3820DWF is an affordable, high-quality printer with double-sided printing, single scanning and fax up to A4 and a 35-page ADF. Perfect for demanding home office or small office settings

Think big with this high-quality multifunction printer with double-sided printing and single scanning and fax all up to A4. You'll stride through tasks with print speeds of up to 21ppm\* in black and a 35 page A4 automatic document feeder (ADF). And that's not forgetting its cost-effective inks and flexible wireless connectivity solutions such as Scan-to-cloud\*.

#### Professional A4 printing

This A4 multifunction printer will meet the needs of even the most demanding home office and small office users. It offers double-sided (duplex) printing and single scanning and faxing all up to A4, plus its automatic document feeder can process up to 35 A4 pages. Furthermore, its PrecisionCore printhead produces high-quality, laser-like prints.

#### Enhance your productivity

This efficient, reliable and fast model offers A4 double-sided printing and print speeds of 21ppm in black and 10ppm in colour\*. It's also simple to operate directly thanks to its intuitive user interface and 6.8cm touchscreen.

#### Minimise your outgoings

Dramatically reduce your costs; this printer is compatible with individual inks which are 50% more efficient compared to tri-colour cartridges\*. Giving great value for money, cartridges are available in standard and XL, with the highest yield delivering up to 1,100 pages\*.

#### Flexible wireless solutions

Print from anywhere in the office with Wi-Fi connectivity or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Epson's free mobile printing apps and solutions provide further versatility; Email Print allows you to send items to print from almost anywhere in the world\*. And with Scan-to-Cloud, you can enjoy the benefits of collaborative working\*.

#### 3 months free ReadyPrint Flex ink subscription\*


For new customers, you can get the first 3 months free when you sign up with code EPSON3. Subscribe and save up to 70% on ink costs\* with ReadyPrint Flex, and never run out of ink again. Your ink levels are monitored and new inks are sent direct to your door, before you run out!

## DATASHEET / BROCHURE



## KEY FEATURES

- **A4 multifunction printer for business quality documents**  
High quality print, copy, scan and fax in one machine, plus 35-page ADF
- **Wireless connectivity lets you print from anywhere**  
Print and scan easily from your smartphone or tablet using the Epson iPrint app, for high-quality document printing\*
- **Save money by only replacing the colour used**  
With Epson's genuine individual inks
- **Money and paper saving double-sided printing**  
Automatically print on both sides to reduce paper usage and save money
- **Enjoy hassle-free ink replacements, delivered to your door, before you run out!**  
First 3 months free ReadyPrint Flex ink subscription\* with code EPSON3
- **Legal Statement**  
Complies with The UK Product Security and Telecommunications Infrastructure (Product Security) requirements. Epson will provide security updates for 7 years from purchase

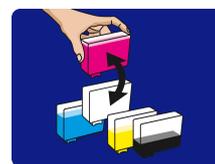

# EPSON®

## PRODUCT SPECIFICATIONS

<b>TECHNOLOGY</b>	
Printing Method	PrecisionCore™ Print Head
Minimum Droplet Size	3.8 pl
Ink Technology	DURABrite™ Ultra
<b>PRINT</b>	
Printing Speed ISO/IEC 24734	21 pages/min Monochrome, 10 pages/min Colour
Duplex Printing Speed	12 A4 Pages/min Monochrome, 7 A4 Pages/min Colour
ISO/IEC 24734	
Maximum Printing Speed	35 pages/min Monochrome (plain paper 75 g/m <sup>2</sup> ), 21 pages/min Colour (plain paper 75 g/m <sup>2</sup> )
Printing Resolution	4,800 x 2,400 DPI
Printing Volume	26,000 pages per month
	The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities.
Recommended Duty Cycle	200 - 1,000 pages per month
Colours	Black [Pigment], Cyan [Pigment], Yellow [Pigment], Magenta [Pigment]
For detailed information on printing speeds please visit <a href="http://www.epson.eu/testing">http://www.epson.eu/testing</a> .	
<b>SCAN</b>	
Optical Resolution	1,200 DPI x 2,400 DPI (Horizontal x Vertical)
Output formats	BMP, JPEG, TIFF, multi-TIFF, PDF, PNG
Scanner type	Contact image sensor (CIS)
<b>FAX</b>	
Fax speed dials (max)	100 names and numbers
Page memory	Up to 180 pages (ITU-T No.1 chart)
Fax Functions	PC Fax, Address Book, Delay Send, Broadcast Fax
<b>PAPER / MEDIA HANDLING</b>	
Paper Formats	A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), B5, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter Legal
Automatic Document Feed	35 pages
Duplex	Yes (A4, plain paper)
Paper Tray Capacity	250 Sheets Maximum
Number of paper trays	1
<b>CONNECTIVITY</b>	
Interfaces	Hi-Speed USB - compatible with USB 2.0 specification, Ethernet interface (100 Base-TX / 10 Base-T), Wireless LAN IEEE 802.11a/b/g/n, Wi-Fi Direct, USB host
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP)
<b>GENERAL</b>	
Energy Use	17 Watt (standalone copying, ISO/IEC 24712 pattern), 1.2 Watt (sleep mode), 6.2 Watt (Ready), 0.2 Watt (Power off), TEC 0.17 kWh/week
Product dimensions	425 x 378 x 249 mm (Width x Depth x Height)
<b>OTHER</b>	
Warranty	12 months Carry in Optional warranty extension available

## LOGISTICS INFORMATION

SKU	C11CJ07401
EAN code	8715946679761
Country of Origin	Indonesia
Layer	2 Units
Layer Block	4 Units

For more information please contact:

Home users: 0343 90 37766  
 Business users\*: 0871 42 37766  
 Republic of Ireland: 01 436 7742  
 Or visit us at <https://www.epson.co.uk/contactus>  
 \* 10p per minute plus network extras.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.  
 Product information is subject to change without prior notice.  
 Last extracted: 2025-12-23

## WorkForce Pro WF-3820DWF Printer

### WHAT'S IN THE BOX

- Individual Ink Cartridges
- Main unit
- Power cable
- Quick Start Guide
- Warranty document
- Driver and utilities

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

	Suitcase 405	Suitcase 405XL
●	350 pages*	1,100 pages*
● ● ● ●	300 pages*	1,100 pages*

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. see [www.epson.co.uk/cartridgefootnotes](http://www.epson.co.uk/cartridgefootnotes)

**EPSON**®