

WorkForce Pro WF-C4310DW

DATASHEET / BROCHURE



Reduce your business printing costs with this A4 inkjet. It offers high-quality, low-cost-printing and flexible wireless solutions.

Stride through tasks with print speeds of up to 21ppm¹ and cost-effective inks. Perfect for the business environment while cutting business' environmental impact and improving CSR reputation.

Print in high quality

This A4 printer will meet the needs of even the most demanding home office and small office users. Furthermore, its PrecisionCore printhead produces high-quality, laser-like prints.

Enhance your productivity

This efficient, reliable and fast model offers A4 double-sided printing and print speeds of 21ppm in black and 11ppm in colour¹. It's also simple to operate directly thanks to its intuitive user interface and 6.1cm touchscreen.

Minimise your outgoings


Dramatically reduce your costs; this printer is compatible with individual inks which are 50% more efficient compared to tri-colour cartridges². Giving great value for money, cartridges are available in standard and XL, with the highest yield delivering up to 2,200 pages³.

Be flexible with wireless solutions

Print from anywhere in the office with Wi-Fi connectivity or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Epson's free mobile printing apps and solutions provide further versatility; Email Print allows you to send items to print from almost anywhere in the world .

KEY FEATURES

- **High-quality A4 Single Function**
Double-sided print
- **Fast business-quality printing**
21ppm in black and 11ppm in colour¹
- **Cost-effective inks**
Individual inks are 50% more efficient compared to tri-colour cartridges²
- **Wireless solutions**
Ethernet, Wi-Fi, and Wi-Fi Direct
- **Epson's free mobile printing apps**
Freedom to print from almost anywhere
- **Legal Statement**
Complies with The UK Product Security and Telecommunications Infrastructure (Product Security) requirements. Epson will provide security updates for 7 years from purchase

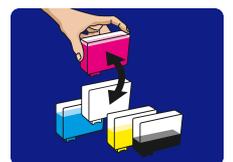

EPSON[®]

PRODUCT SPECIFICATIONS

TECHNOLOGY

Printing Method	PrecisionCore™ Print Head
Nozzle Configuration	800 Nozzles Black, 256 Nozzles per Color
Minimum Droplet Size	3.8 pl, With Variable-Sized Droplet Technology
Ink Technology	DURABrite™ Ultra
Category	Home Office, Office Desktop
All-in-One Functions	Print

PRINT

Number of colours	4 colour
First Page Out	Monochrome6.3 Seconds, Colour9.3 Seconds
Printing Speed ISO/IEC 24734	21 pages/min Monochrome, 11 pages/min Colour
Printing Resolution	4,800 x 2,400 DPI
Printing Volume	33,000 pages per month The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities.
Colours	Black [Pigment], Cyan [Pigment], Yellow [Pigment], Magenta [Pigment]
Print from	PC, MAC, Mobile Device

PAPER / MEDIA HANDLING

Paper Formats	Letter, A4 (21.0x29.7 cm)
Automatic Document Feed	Yes
Compatible Paper Weight	64 - 255g/m ² Paper compatibility may vary by printer. Third party media may not be compatible. See printer's online User's Guide for suitable Epson paper and note that 300gsm, where applicable, is based on Epson Ultra Glossy Photo Paper
Duplex	Yes (A4, plain paper)
Output Tray Capacity	Output Tray 1:250 Sheets
Paper Tray Capacity	250 Sheets Maximum
Number of paper trays	1

PAPER FEED RASF

Paper Input Name	RASF
Paper Formats	A4, Letter
Paper Capacity 1	80

PAPER FEED C1

Paper Input Name	C1
Paper Formats	A4, Letter
Paper Capacity 1	250

CONNECTIVITY

Network Printing Protocols	TCP/IPv4, TCP/IPv6, SMB 2.0
Network Management Protocols	SNMP, HTTP, DHCP, TCP/IPv4, TCP/IPv6, HTTPS
Network Protocol	HTTPS, IPv4, IPv6
Interfaces	Wi-Fi Direct, Hi-Speed USB - compatible with USB 2.0 specification, Wireless LAN IEEE 802.11b/g/n, Ethernet interface (100 Base-TX / 10 Base-T)
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES), WPA3-SAE(AES)
Mobile and Cloud printing services	Epson Connect (iPrint, Email Print), Apple AirPrint, Mopria Print Service, Mopria Scan, Epson iPrint App
Network Protocol	TCP/IPv4, TCP/IPv6, HTTP, HTTPS

WorkForce Pro WF-C4310DW

WHAT'S IN THE BOX

- Individual Ink Cartridges
- Quick Start Guide
- Warranty document
- Power cable

PRODUCT SPECIFICATIONS

GENERAL

Recommended number of users	From:1 To:4
Energy Use	4.8 Watt (Ready), 0.2 Watt (Power off), 0.9 Watt (sleep mode), 23 Watt (Printing), TEC 0.14 kWh/week
Supply Voltage	AC 100 V - 120 V
Product dimensions	425 x 378 x 164 mm (Width x Depth x Height)
Product weight	5.8 kg
Compatible Operating Systems	Mac OS X 10.6.8 or later, Windows 10 (32/64 bit), Windows 7 (32/64 bit), Windows 8 (32/64 bit), Windows 8.1 (32/64 bit), Windows Server 2008 (32/64bit), Windows Server 2008 R2, Windows Server 2012 (64bit), Windows Server 2012 R2, Windows Server 2016, Windows Vista (32/64 bit), Windows XP Professional x64 Edition SP2 or later, Windows XP SP3 or later (32-bit), Windows Server 2003 R2, Windows Server 2003 SP2 or later
Sound Power	Operation:5.3 B (A)
Noise	Operation:53 dB (A)

ADDITIONAL FEATURES

Panel	Type: Color, Diagonal:6.1 cm
-------	------------------------------

PRODUCT SAFETY

Product Safety Warnings	Contains 1,2-benzisothiazol-3(2H)-one. May produce an allergic reaction. Contains 2,4,7,9-tetramethyldec-5-yne-4,7-diol. May produce an allergic reaction. Contains 2-methylisothiazol-3(2H)-one. May produce an allergic reaction. Always follow the information on the product label.
-------------------------	--

OTHER FEATURES

Emulations	ESC/P-R
------------	---------

OTHER

Warranty	12 months On-site service Optional warranty extension available
----------	--

LOGISTICS INFORMATION

SKU	C11CK18401CA
EAN code	8715946703817
Country of Origin	Indonesia
Layer	2 Units
Layer Block	4 Units

For more information please contact:

Home users: 0343 90 37766
Business users*: 0871 42 37766
Republic of Ireland: 01 436 7742
Or visit us at <https://www.epson.co.uk/contactus>
* 10p per minute plus network extras.

Web: www.epson.co.uk
www.epson.ie

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.
Product information is subject to change without prior notice.
Last extracted: 2025-09-05

WorkForce Pro WF-C4310DW

INK YIELD DATA



Spectacles 408XL



1,700 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

INK CARTRIDGE COMPATIBILITY

● 408

● 408

● 408

● 408



1. Determined in accordance with ISO/IEC 24734 showing the average of ESAT from the Office Category Test for default A4 simplex. For more information, please visit www.epson.eu/testing
2. Based on testing carried out by BLI in July 2019, compared to equivalent competitor (HP and Canon) printer models, using tri-colour cartridges, according to the manufacturers' websites, July 2018. Weighting for Document and Photo printing applied based on TNS 'Printing Usage & Attitudes Study', June 2013.
3. Approx. page yield based on ISO/IEC 24711/24712. Actual yield will vary depending on images printed and usage conditions. For more information visit www.epson.eu/pageyield
4. Epson iPrint requires a wireless connection and the Epson printing app. Epson Email print, Epson Remote Print Driver and Epson Scan-to-Cloud require an internet connection. For more information, supported languages and devices, please visit www.epsonconnect.eu
- 5.
6. WARNING: when printing on glossy photo paper ink drying time will be considerably extended

EPSON[®]