

# WorkForce WF-2960DWF



## DATASHEET / BROCHURE



The WF-2960DWF is an affordable, compact A4 inkjet printer with many essential business features, like A4 double-sided printing, 30-page ADF for copying, scanning and faxing & 6.1cm LCD touchscreen, for your home office or small office.

You'll be surprised just how many essential business features this affordable and compact multifunction inkjet printer packs in. Connect easily via Wi-Fi and Wi-Fi Direct and print in the way that suits you with Epson Connect\* and Apple AirPrint\*. Thanks to the Automatic Document Feeder (ADF) and double-sided printing, you can use your time and budget more efficiently.

### Compact and stylish

There's no need to waste space; this multifunction printer features a compact design. With its sleek and refined form, it's easy to integrate into any home or small office.

Speed through tasks with double-sided printing, 150-sheet front-loading paper tray and 30-page ADF for multi-page scanning, copying and faxing. Navigation is easy with its large LCD touch-screen and interface.

### Easy to use

Epson's four-colour 503 Chillies inks give reliable and clear prints with minimal outlay. In addition to reducing your printing costs with affordable, individual inks in standard and XL cartridges.

### Minimise your outgoings

Print from anywhere with Wi-Fi connectivity, or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Plus, with Epson's Smart Panel app you can print documents, monitor and troubleshoot\* all from your device.


### Flexible wireless solutions

For new customers, you can get the first 3 months free when you sign up with code EPSON3. Subscribe and save up to 70% on ink costs\* with ReadyPrint Flex, and never run out of ink again. Your ink levels are monitored and new inks are sent direct to your door, before you run out!

**3 months free ReadyPrint Flex ink subscription\***

## KEY FEATURES

- **A4 multifunction printer for business quality documents**  
High quality print, copy, scan and fax in one machine, plus 30-page ADF
- **Wireless connectivity lets you print from anywhere**  
Use the Epson Smart Panel app to set up, monitor, print and more from your mobile
- **Save money by only replacing the colour used**  
With Epson's genuine individual inks
- **Money and paper saving double-sided printing**  
Automatically print on both sides to reduce paper usage and save money
- **Enjoy hassle-free ink replacements, delivered to your door, before you run out!**  
First 3 months free ReadyPrint Flex ink subscription\* with code EPSON3
- **Legal Statement**  
Complies with The UK Product Security and Telecommunications Infrastructure (Product Security) requirements. Epson will provide security updates for 7 years from purchase

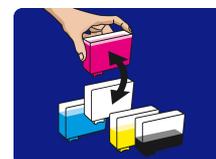

**EPSON®**

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

|                      |  |
|----------------------|--|
| Printing Method      | 4-colour inkjet printer                        |
| Minimum Droplet Size | 3.3 pl, With Variable-Sized Droplet Technology |
| Ink Technology       | Pigment black and Dye colour inks              |

### PRINT

|                              |   |
|------------------------------|---|
| Printing Speed ISO/IEC 24734 | 14 pages/min Monochrome, 7.5 pages/min Colour   |
| Duplex Printing Speed        | 6.5 A4 Pages/min Monochrome, 4.5 A4 Pages/min Colour  |
| ISO/IEC 24734                |   |
| Maximum Printing Speed       | 33 pages/min Monochrome (plain paper 75 g/m <sup>2</sup> ), 20 pages/min Colour (plain paper 75 g/m <sup>2</sup> )  |
| Printing Resolution          | 4,800 x 1,200 DPI   |
| Printing Volume              | 3,000 pages per month   |
|                              | The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities. |
| Colours                      | Black, Cyan, Yellow, Magenta  |

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

### SCAN

|                    |   |
|--------------------|---|
| Optical Resolution | 1,200 DPI x 2,400 DPI (Horizontal x Vertical) |
| Scanner type       | Contact image sensor (CIS)                    |

### FAX

|                       |   |
|-----------------------|---|
| Fax speed dials (max) | 100 names and numbers   |
| Page memory           | Up to 100 pages (ITU-T No.1 chart)  |
| Fax Functions         | PC Fax, Auto Redial, Speed Dial, Address Book, Broadcast Fax, Polling Reception |

### PAPER / MEDIA HANDLING

|                         |   |
|-------------------------|---|
| Paper Formats           | A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), B5, B6, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 10 x 15 cm, 13 x 18 cm, 16:9, User defined, C4 (Envelope) |
| Automatic Document Feed | 30 pages  |
| Duplex                  | Yes (A4, plain paper)   |
| Paper Tray Capacity     | 150 Sheets Standard, 20 Photo Sheets  |
| Number of paper trays   | 1   |

### CONNECTIVITY

|               |   |
|---------------|---|
| Interfaces    | Hi-Speed USB - compatible with USB 2.0 specification, Wireless LAN IEEE 802.11b/g/n, Wi-Fi Direct, Ethernet interface (100 Base-TX / 10 Base-T) |
| WLAN Security | WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES), WPA3-SAE(AES)  |

### GENERAL

|            |  |
|------------|--|
| Energy Use | 12 Watt (standalone copying, ISO/IEC 24712 pattern), 1 Watt (sleep mode), 5.4 Watt (Ready), 0.2 Watt (Power off) |
|------------|--|

### OTHER

|          |   |
|----------|---|
| Warranty | 12 months Carry in<br>Optional warranty extension available |
|----------|---|

## LOGISTICS INFORMATION

|                   |               |
|-------------------|---------------|
| SKU               | C11CK60401    |
| EAN code          | 8715946702513 |
| Country of Origin | Philippines   |
| Layer             | 2 Units       |
| Layer Block       | 4 Units       |



For more information please contact:

Home users: 0343 90 37766  
Business users\*: 0871 42 37766  
Republic of Ireland: 01 436 7742  
Or visit us at <https://www.epson.co.uk/contactus>  
\* 10p per minute plus network extras.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.  
Product information is subject to change without prior notice.  
Last extracted: 2025-08-20

## WorkForce WF-2960DWF

### WHAT'S IN THE BOX

- Individual Ink Cartridges
- Main unit
- Power cable
- Setup guide
- Warranty document

### INK CARTRIDGE COMPATIBILITY



### INK YIELD DATA

|  |              |                |
|--|--------------|----------------|
|  | Chillies 503 | Chillies 503XL |
| ●  | 210 pages*   | 550 pages*     |
| ● ● ●  | 165 pages*   | 470 pages*     |

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. see [www.epson.co.uk/cartridgefootnotes](http://www.epson.co.uk/cartridgefootnotes)

**EPSON**<sup>®</sup>