


WorkForce WF-2910DWF



DATASHEET / BROCHURE

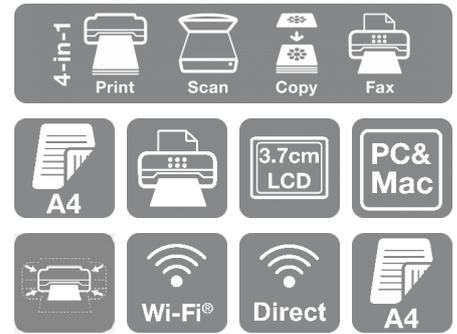

The WF-2910DWF is an affordable, compact A4 inkjet printer with many essential business features, like A4 double-sided printing and wireless connectivity, for your home office or small office.

This multifunction inkjet printer with Wi-Fi is stylish, compact and easy-to-use in your home office. Reduce waste and costs with A4 double-sided printing and affordable individual inks. Printing with devices on the go is easy, with Wi-Fi, Wi-Fi Direct, Epson Connect, the Epson Smart Panel app* and Apple AirPrint*.

Compact and stylish

With its sleek and refined form, it's easy to integrate this space-saving, multifunction model into any home office.

The printer's functions are easy to navigate, thanks to the intuitive user interface and LCD screen. Save paper and money with A4 double-sided printing.

Easy to use

Epson's four-colour Pineapple 604 inks provide reliable and clear prints with minimal outlay. In addition to reducing your printing costs with affordable, individual inks in standard and XL cartridges.

Minimise your outgoings

Print from anywhere in your home or office, with Wi-Fi connectivity. Or use Wi-Fi Direct to print from compatible wireless devices without a Wi-Fi network. Plus, with Epson's Smart Panel app you can control your printer from your device, printing documents, monitoring and troubleshooting*.


Flexible wireless solutions

For new customers, you can get the first 3 months free when you sign up with code EPSON3. Subscribe and save up to 70% on ink costs* with ReadyPrint Flex, and never run out of ink again. Your ink levels are monitored and new inks are sent direct to your door, before you run out!

3 months free ReadyPrint Flex ink subscription*

KEY FEATURES

- **A4 multifunction printer for business quality documents**
High quality print, copy, scan and fax in one machine
- **Wireless connectivity lets you print from anywhere**
Use the Epson Smart Panel app to set up, monitor, print and more from your mobile
- **Save money by only replacing the colour used**
With Epson's genuine individual inks
- **Money and paper saving double-sided printing**
Automatically print on both sides to reduce paper usage and save money
- **Enjoy hassle-free ink replacements, delivered to your door, before you run out!**
First 3 months free ReadyPrint Flex ink subscription* with code EPSON3
- **Legal Statement**
Complies with The UK Product Security and Telecommunications Infrastructure (Product Security) requirements. Epson will provide security updates for 7 years from purchase

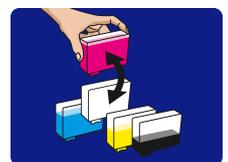

PRODUCT SPECIFICATIONS

TECHNOLOGY

Printing Method	4-colour inkjet printer
Minimum Droplet Size	3 pl
Ink Technology	Pigment black and Dye colour Inks

PRINT

Printing Speed ISO/IEC 24734	10 pages/min Monochrome, 5 pages/min Colour
Maximum Printing Speed	33 pages/min Monochrome (plain paper 75 g/m ²), 18 pages/min Colour (plain paper 75 g/m ²), 42 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper)
Printing Resolution	5,760 x 1,440 DPI
Printing Volume	3,000 pages per month The maximum number of printed pages per month based on the performance capabilities of the printer, including ISO rated print speeds and paper handling capabilities.
Colours	Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

SCAN

Optical Resolution	1,200 DPI x 2,400 DPI (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

FAX

Fax speed dials (max)	100 names and numbers
Page memory	Up to 100 pages (ITU-T No.1 chart)
Fax Functions	PC Fax, Memory Reception, Auto Redial, Speed Dial, Address Book, Broadcast Fax, Polling Reception

PAPER / MEDIA HANDLING

Paper Formats	A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), B5, B6, C6 (Envelope), DL (Envelope), No. 10 (Envelope), Letter, 10 x 15 cm, 13 x 18 cm, 16:9, User defined
Duplex	Yes (A4, plain paper)
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets
Number of paper trays	1

CONNECTIVITY

Interfaces	Hi-Speed USB - compatible with USB 2.0 specification, Wireless LAN IEEE 802.11b/g/n, Wi-Fi Direct
WLAN Security	WEP 64 Bit, WEP 128 Bit, WPA PSK (TKIP), WPA2 PSK (AES), WPA3-SAE(AES)

GENERAL

Energy Use	12 Watt (standalone copying, ISO/IEC 24712 pattern), 0.7 Watt (sleep mode), 4.6 Watt (Ready), 0.2 Watt (Power off)
Product dimensions	375 x 300 x 170 mm (Width x Depth x Height)
Product weight	4.4 kg
Noise Level	5.1 B (A) according to ISO 7779 pattern with Epson Premium Glossy Photo Paper / Photo RPM mode - 37 dB (A) according to ISO 9296

ADDITIONAL FEATURES

Panel	Type: Color, Diagonal:3.7 cm
-------	------------------------------

OTHER

Warranty	12 months Carry in Optional warranty extension available
----------	---

LOGISTICS INFORMATION

SKU	C11CK64401
EAN code	8715946702599
Country of Origin	Indonesia



For more information please contact:

Home users: 0343 90 37766
Business users*: 0871 42 37766
Republic of Ireland: 01 436 7742
Or visit us at <https://www.epson.co.uk/contactus>
* 10p per minute plus network extras.

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.
Product information is subject to change without prior notice.
Last extracted: 2025-08-20

Web: www.epson.co.uk
www.epson.ie

WorkForce WF-2910DWF

WHAT'S IN THE BOX

- Individual Ink Cartridges
- Main unit
- Power cable
- Setup guide
- Warranty document

INK CARTRIDGE COMPATIBILITY



INK YIELD DATA

	Pineapple 604	Pineapple 604XL
●	150 pages*	500 pages*
● ● ● ●	130 pages*	350 pages*

* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

1. see www.epson.co.uk/cartridgefootnotes

EPSON®