


RHT313 Indoor/Outdoor Hygro-Thermometer

Simultaneous display of Indoor/Outdoor Temperature and Humidity

Features:

- Temperature ranges:
 - Indoor: 32 to 122°F (0 to 50°C)
 - Outdoor: -58 to 158°F (-50 to 70°C)
- Humidity range: 10 to 99%RH
- °F/°C switchable
- Min/Max records the highest and lowest readings of both indoor and outdoor temperature/humidity
- Includes internal and outdoor temperature/humidity sensor with 3ft (1m) cable, built-in stand, and AAA battery
- 1-year warranty

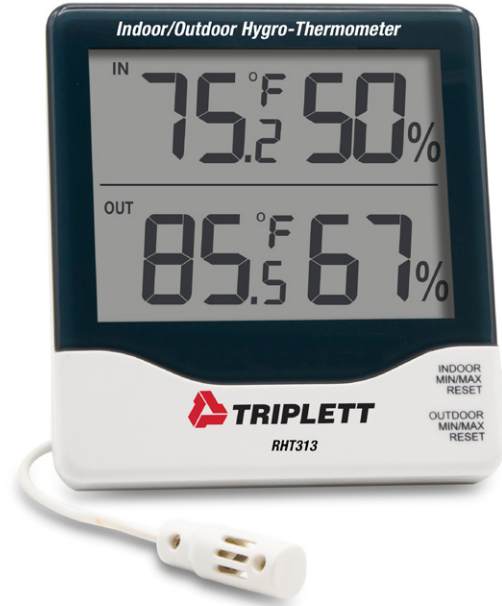

Applications:

Building inspection, water restoration, greenhouses, warehouses, museums, libraries, offices, hospitals, storage areas

Specifications

Indoor Air Temperature	32 to 122°F (0 to 50°C)
Outdoor Air Temperature	-58 to 158°F (-50 to 70°C)
Accuracy	±2°F/1°C
Indoor/Outdoor Humidity	10 to 99%RH
Accuracy	±5%RH
Resolution	0.1°F/°C, 1%RH
Power	AAA Battery
Dimensions	4.25 x 4 x 0.8" (110 x 102 x 20mm)
Weight	5oz (142g)

Ordering Information:

RHT313 Indoor/Outdoor Hygro-Thermometer

