




Acer CE270U X

OLED prosumer display

- 26.5" WQHD (2560x1440) monitor
- QD-OLED
- 240Hz refresh rate, with DRR for 240Hz and 60Hz
- 0.03ms (GTG)
- DCI-P3 99% wide color gamut
- HDR10 support
- Delta E<2 high color accuracy
- AMD FreeSync Premium (applying)
- Ergostand with tilt, swivel, pivot, and height adjustment
- PIP/PBP
- 100% paper packaging
- BlueLightShield Pro



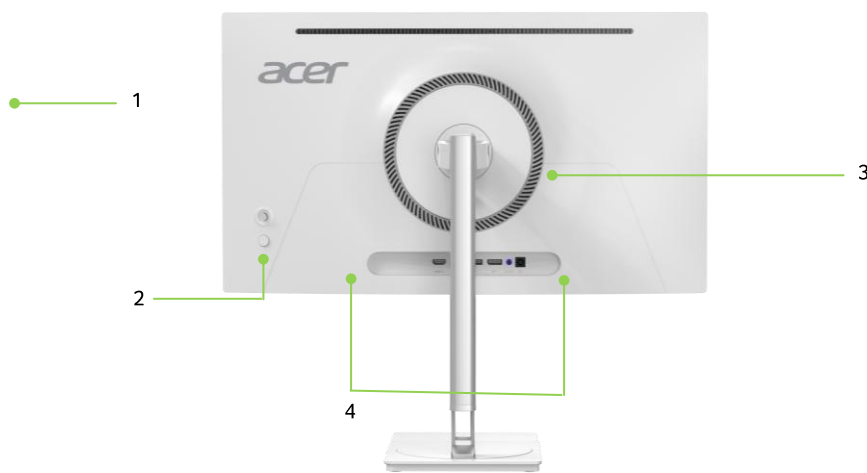

Product views	1. 26.5" 16:9 display 2. Power button/OSD button	3. VESA wall mount 4. 3Wx2 speaker
Color	White	
Dimensions and weight	Dimensions: 61.11 (W) x 55.30~40.30 (H) x 19.6 (D) cm 24.06 (W) x 21.77~15.87 (H) x 7.72 (D) inch	Weight: 5.15 kg. 11.33 lb.
Size	26.5" (16:9)	
Active display area	590x334 mm	
Maximum resolution	HDMI:2560x1440@240Hz DP:2560x1440@240Hz	
	DCI-P3 99%	QD-OLED
Response time	0.03ms (GTG)	
Contrast ratio	1,500,000:1 (Native)	
Brightness	Typ. 200nits, Peak 400nits @ HDR 10%	
Viewing angle (CR=10)	178° (H), 178° (V)	
Colors	1.07B	
Bits	10bit	
Input signal	2HDMI(2.1)+2DisplayPort(1.4)+SPK+Audio out	
Speakers	3Wx2	
VESA Wall mounting	100 X 100mm	
Power supply	External (C5/C6)	
Tear Technology	AMD FreeSync Premium (applying)	
ErgoStand	Tilt • -5° ~ 25° Swivel • ±178°	Height adjustment • 150 mm Pivot • ±90°

About Acer

Established in 1976, Acer is an information and communication technology company dedicated to the research, design, marketing, sale and support of innovative products that enhance people's lives. Acer's green supply chain delivers environmentally friendly PCs, displays, projectors, servers, tablets and smartphones — tools our customers need to explore beyond limits and experience more. Ranked No. 3 for notebooks globally (IDC 2012), Acer employs 8,000 people, and 2011 revenues reached US\$15.7 billion. Please visit www.acer.com for more information.

