



Portable Monitor LIGHT FHD 1080p Touch & Non-Touch

PN: 32400, 32401, 32402

Description

Verbatim's Portable Monitors LIGHT series is designed for users who require high-quality, compact displays for productivity and entertainment on the go.


The family comprises three models: a 14" touchscreen, a 15.6" touchscreen, and a 15.6" non-touch. Each model features a Full HD (1920 × 1080) resolution with an IPS panel, delivering sharp images and consistent colour reproduction across a 178° wide viewing angle.

With an ultra-slim and lightweight design, integrated speakers, and an audio jack, these monitors offer versatile functionality.

All units include a protective neoprene sleeve for secure and convenient portability.

- Full HD Resolution (1920 × 1080) with 16:9 Aspect Ratio & 16.7 million colours
- Touchscreen version uses 10-Point Capacitive Multi-Touch for fast and precise touch control thanks to the Glass+Glass Touch Panel.
- Easy USB-C Connection – plug & play, one cable for video, power, and touch (where available)
- IPS Panel with 178° Viewing Angle – clear images from any direction
- HDR Technology – enhanced picture quality and vibrant colours
- Wide Device Compatibility – works with PC, Mac, tablets, smartphones, and consoles via USB-C or HDMI
- Ultra-Slim & Lightweight Design – perfect for travel and mobile work
- Built-In Speakers & Audio Jack – no extra sound system needed
- Multi-lingual On Screen Display

* Only for Windows

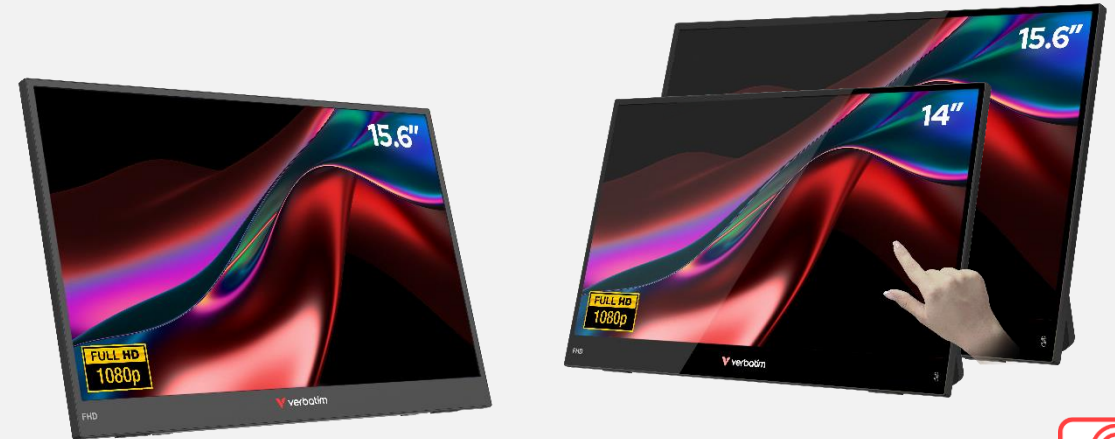

Portable Monitor LIGHT

FHD 1080p Touch & Non-Touch



PN: 32400, 32401, 32402

PN	Panel	Size	Resolution (H x V)	Touch	Wall Mounting	Power	Video	Case	Weight
32400	IPS	14"	FHD 1920x1080	Capacitive G+G, Multi-Touch	2 screw threads, 75mm apart	USB-C	USB-C / Mini HDMI	Plastic	778.2 g
32401		15.6		No					682.0 g
32402		15.6		Capacitive G+G, Multi-Touch					973.2 g

Features

Brightness (typical): 220-250cd/m² (Typ.)

NTSC: 45%

Contrast (typical): 1000:1 (Typ.)

Refresh rate: 60 Hz

Active area (mm): 14" 309.31×173.99, 15.6" 344.16×193.59 mm (H×V)

Pixel pitch (mm): 14" 161.1×161.1, 15.6": 179.25×179.25 um (H×V)

Resolution (H x V): 1920*1080

Aspect ratio: 16:9

Response Time:

Typical GTG:10ms, Typical Tr+Tf: 20ms, Btw: 20ms

View angles LR,DU (CR>10): 89/89/89/89 (Typ.)(CR>10)

OS Compatibility

- Android OS
- Windows 11/10/8
- Mac OS
- iOS (Adapter required for Lightning devices, not included; **Touchscreen function not supported by iOS/iPadOS where available**)

Languages


Front of pack: English

Back and Side of Pack: Product info in English, French, Spanish

Back of Pack: English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Slovakian, Croatian, Serbian, Romanian, Turkish, Traditional Chinese, Simplified Chinese, Korean, Japanese

Quick Installation Languages:

English, French, German, Traditional Chinese + Technical Support text in English, French, German, Dutch, Italian, Spanish, Portuguese, Polish, Russian, Czech, Hungarian, Croatian, Serbian, Slovakian, Romanian, Turkish, Traditional Chinese, Simplified Chinese, Korean, Japanese

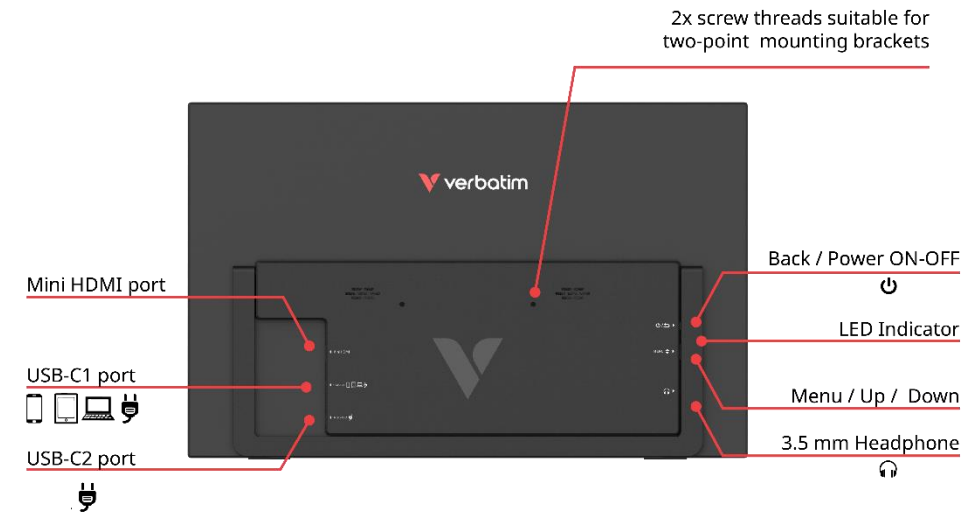

Portable Monitor LIGHT FHD 1080p Touch & Non-Touch

Reorder No.	Description	Tariff Code	Barcode	EAN-128	EAN-14
32400	Verbatim Portable 14" FHD Touch Monitor LIGHT	8528521210	023942324003	(02)00023942324003(37)02(91)863 (02)00023942324003(37)06(91)863	20023942324007 50023942324008
32401	Verbatim Portable 15.6" FHD Monitor LIGHT	8528521210	023942324010	(02)00023942324010(37)02(91)863 (02)00023942324010(37)06(91)863	20023942324014 50023942324015
32402	Verbatim Portable 15.6" FHD Touch Monitor LIGHT	8528521210	023942324027	(02)00023942324027(37)02(91)863 (02)00023942324027(37)06(91)863	20023942324021 50023942324022

Reorder No.	32400	32401	32402
Product Dimensions L x W x H	320.8 x 203.9 x 17.34 mm	355.5 x 221.5 x 17.25 mm	355.8 x 222.3 x 17.68 mm
Product Weight	778.2 g	682 g	973.2 g
Units per Pack	1		
Pack Dimensions L x W x H	462.6 x 280 x 57.5 mm		
Pack Weight	1830 g	1736 g	2028 g
Units per Inner Carton	2		
Inner Carton Dimensions L x W x H	490 x 300 x 130 mm		
Inner Carton Weight	3760 g	4054 g	4070 g
Units per Outer Carton	6		
Outer Carton Dimensions L x W x H	520 x 440 x 330 mm	510 x 460 x 325 mm	520 x 440 x 330 mm
Outer Cartons Weight	13138 g	13246 g	14314 g
Outer Cartons per Layer	4		
Layers per Pallet	3		
Units per Pallet	72		

Pack Content :

- Verbatim Portable Monitor
- USB-C to USB-C cable (1.0m)
- USB-A to USB-C cable (1.0m)
- Mini HDMI-HDMI cable (1.0m)
- EU power supply with UK adapter (5V, 2A)
- Neoprene protection sleeve
- Quick Installation Guide

