




SH CONNECTOR



**1.0mm Pitch/Wire-to-Board Connectors
Crimp Style and Mating Style**

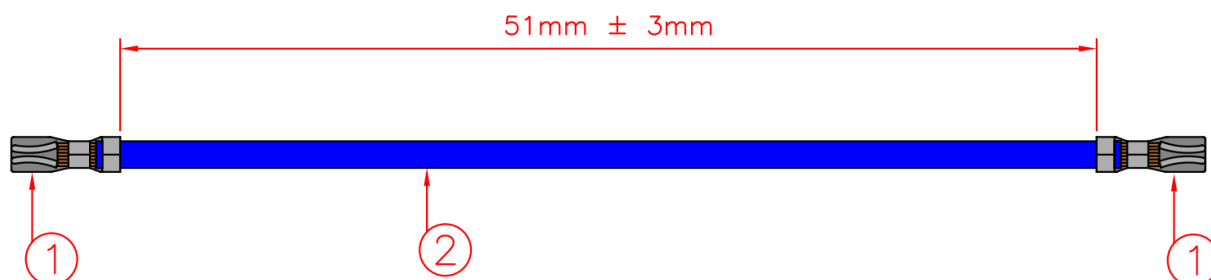

Part Number:

- ASSHSSH28B51

Description:

- JST Series – [SH Series](#)
- Pitch – 1mm
- Cable length (inside dimension) – 51mm

Material Specification:

- (1) Terminal: SSH-003T-P0.2-H
- (2) Cable Type: UL1571
- (2) Cable Size: 28AWG
- (2) Cable Colour: Blue

Quality

- We trust and believe in our product. Each step of our development and manufacturing process is focused on delivering a fault-free product. JST does not compromise on quality.

Applicable Housings:

No. of Circuits	Part Number With Protrusions	Part Number Without Protrusions
2	SHR-02V-S-B	SHR-02V-S
3	SHR-03V-S-B	SHR-03V-S
4	SHR-04V-S-B	SHR-04V-S
5	SHR-05V-S-B	SHR-05V-S
6	SHR-06V-S-B	SHR-06V-S
7	SHR-07V-S-B	SHR-07V-S
8	SHR-08V-S-B	SHR-08V-S
9	SHR-09V-S-B	SHR-09V-S
10	SHR-10V-S-B	SHR-10V-S
11	SHR-11V-S-B	SHR-11V-S
12	SHR-12V-S-B	SHR-12V-S
13	SHR-13V-S-B	SHR-13V-S
14	SHR-14V-S-B	SHR-14V-S
15	SHR-15V-S-B	SHR-15V-S
16	SHR-16V-S-B	---
20	SHR-20V-S-B	---

Additional Information:


Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing jukma@jst.co.uk



SH CONNECTOR

JST
The Quality Connection

1.0mm Pitch/Wire-to-Board Connectors
Crimp Style and Mating Style

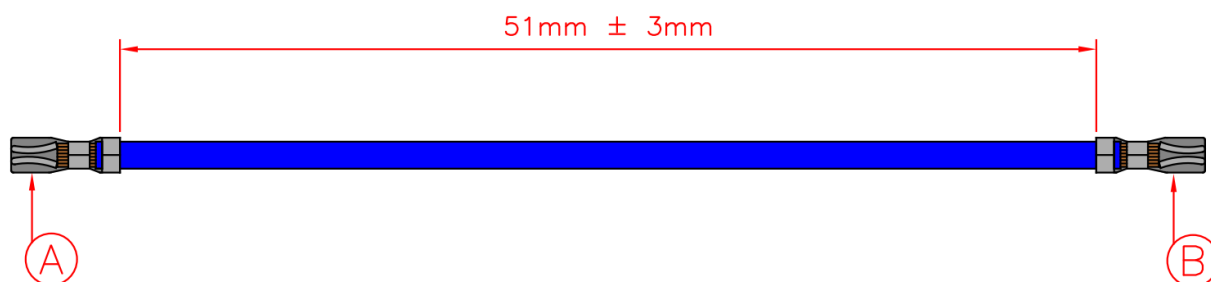

A SSH SSH 28 B 51

Supply Form: Assembled Wire

Terminal Part Number end A: SSH-003T-P0.2-H

Terminal Part Number end B: SSH-003T-P0.2-H

Cable Size: 28awg (??AWG)

Cable Colour: B (Blue), K (Black), R (Red), N (Brown), H (Grey)
O (Orange), Y (Yellow), W (White), M (Green), P (Purple), PK (Pink)

Cable Length: 51mm (????mm)

Additional Information:

Alternative colour and length cables are available upon request, please contact JST for further details by e-mailing jukma@jst.co.uk