

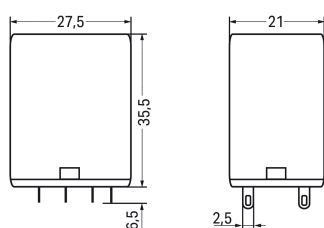
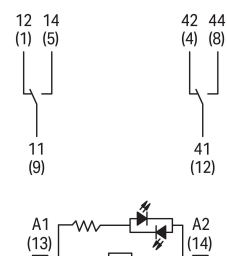


Data Sheet | Item Number: 2585-124

Basic relay; Nominal input voltage: 24 VDC; 2 changeover contacts; Limiting continuous current: 10 A; with manual operation; Module width: 21 mm; Module height: 35mm

<https://www.wago.com/2585-124>

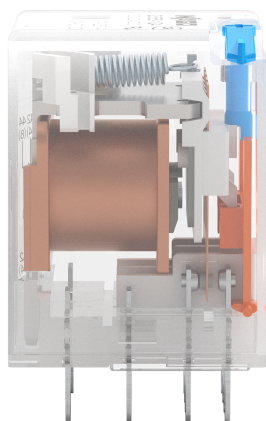

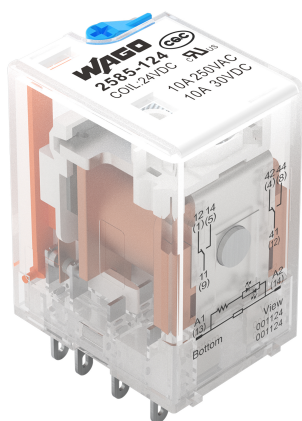

Technical data

Control circuit		Load circuit	
Nominal input voltage U_N	24 VDC	Number of changeover/switchover contacts	2
Input voltage range	19.2 ... 26.4 VDC	Contact material (relay)	AgSnO ₂
Nominal input current at U_N	37 mA	Limiting continuous current	10 A
		Inrush current (resistive) max.	(AC) 30 A / 0.03 s
		Switching Voltage, Max.	250 VAC; 30 VDC
		Switching power (resistive) max.	AC 2500 VA; DC 300 W
		Utilization category	AC-15: 3 A / 250 VAC DC-13: 2 A / 30 VDC
		Recommended minimum load	5 V / 100 mA
		Pull-in time (typ.)	25 ms
		Drop-out time (typ.)	25 ms
		Bounce time (typ.)	4 ms
		Electrical life (NO; resistive load; 23 °C)	100 x 10 ³ switching operations
		Mechanical life	10 x 10 ⁶ switching operations

Signaling	
Status indicator	Yellow LED Mechanical

Safety and protection

Dielectric strength (control/load circuit) (AC, 1 min)	2.5 kVrms
Dielectric strength (open contact) (AC, 1 min)	1.5 kVrms
Dielectric strength (load/load circuit) (AC, 1 min)	2.5 kVrms
Protection type	IP20

Physical data

Width	21 mm / 0.827 inches
Height from the surface	35.5 mm / 1.398 inches
Depth	27.5 mm / 1.083 inches

Mechanical data

Mounting type	Pluggable module
---------------	------------------

Material data

Note (material data)	Information on material specifications can be found here
Weight	35 g

Environmental requirements


Ambient temperature (operation at U_N)	-40 ... +70 °C
Ambient temperature (storage)	-40 ... +70 °C
Relative humidity	20 ... 80 % (no condensation permissible)

PU (SPU)	10 pcs
Packaging type	Box
Country of origin	CN
GTIN	4066966667103
Customs tariff number	85364900990

UNSPSC	39122334
ETIM 9.0	EC001437
ETIM 10.0	EC001437
ECCN	NO US CLASSIFICATION

RoHS Compliance Status	Compliant, No Exemption
------------------------	-------------------------

General approvals	
-------------------	--

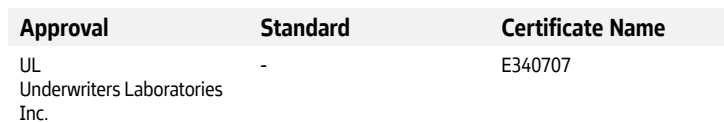

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 2585-124	

CAD data	
2D/3D Models 2585-124	



1 Compatible Products
1.1 Optional Accessories
1.1.1 Socket
1.1.1.1 Socket without relay



Item No.: 2585-102
Relay socket; 2 changeover contacts