


***SPEEDY*LOK Locking Category 5e RJ45 Plug**

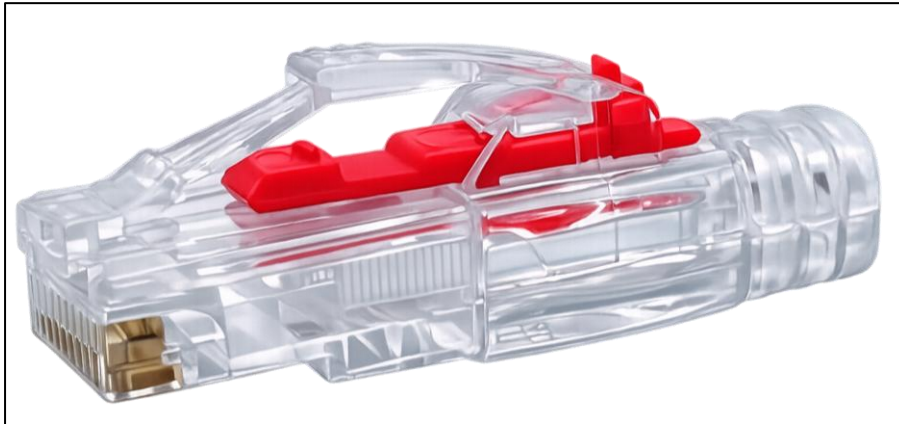

***SPEEDY*LOK Locking Category 5e RJ45 Plug (PXSPDY5LP)**

Our ***SPEEDY*LOK** Category 5e unshielded locking plug is perfect for assemblies which are secure against unauthorised or inadvertent disconnection of critical network connections. A high-performance termination is achieved quickly and with minimum effort due to use of a

SPEEDY RJ45 feedthrough plug

Features

- Perfect solution for rapid termination
- Tamper Resistant – Secure lock locks in the plug for added physical security
- Compliant with Category 5e patch cord standard.
- Should be terminated with crimp tool for feedthrough plugs, such as our TRCSPDY5
- Each plug allows twisted pair wires to be inserted through the body and pulled out of the front to ensure the correct wiring order before crimping
- By pulling the cores into the plug, twists can easily be maintained up to the contacts, enabling fully rated category performance
- Three prong contact blades are suitable for stranded or solid UTP cables cores from 24-26 AWG (0.51 – 0.40mm), with insulation up to 1.0mm O.D. with sheath O.D. of 5.0 – 6.0mm
- Extended hood prevents latch snagging

NOTE: Removal tool (code: TPS) required to release lock

Specifications

- Weight: 3g (including primary packaging)
- Dimensions: 60x30x10mm (in primary packaging)
- Materials:
 - Housing: Polycarbonate UL94V-0
 - Colour: Transparent with red secure lock
 - Contact pin: 50"μ/1.27 μm gold plating over nickel over phosphor bronze
 - Boot: Crystal polycarbonate
- Operating temperature: -40 – 70°C

Packaging:

PXSPDY5LP: Packed in individual poly bags then in bags of 10

PXSPDY5LP#10: Packed in bags of 10 then in bags of 100


EAN number:

PXSPDY5LP: 5055386514332

PXSPDY5LP#10: 5055386514363

Commodity Code: 85444920

Country of Origin: China

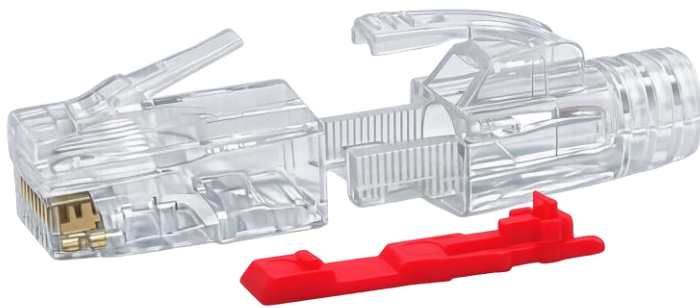


PXSPDY5LP components



Removal tool (TPS)

ROHS Compliant

Code: PXSPDY5LP

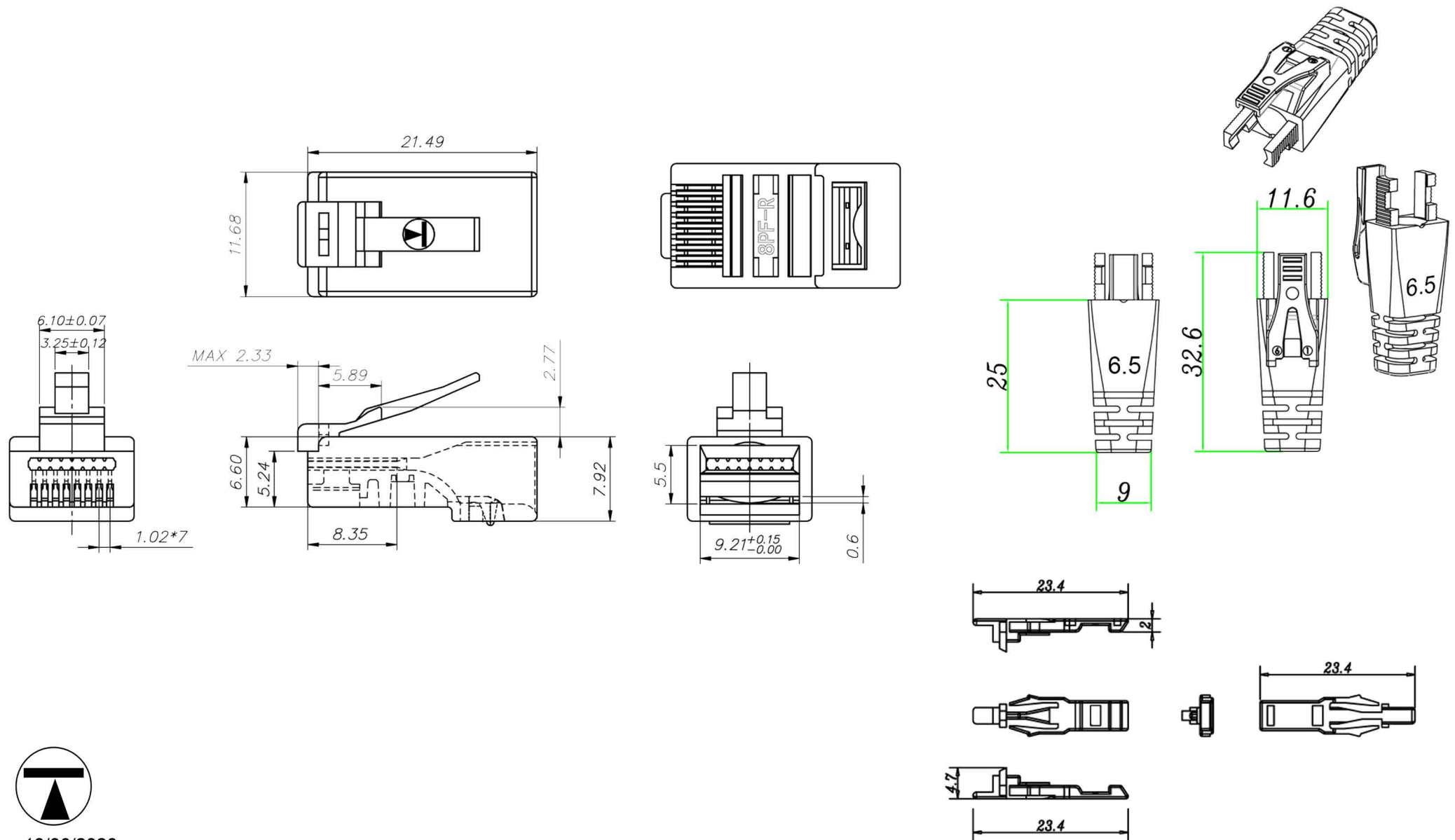

10/06/2026