

# PHILIPS



## True wireless headphones

Small buds. Great value

Natural sound. Dynamic bass

Pocket-sized charging case

Comfy SecureFit ear tips



TAT1300PK

## Feel the beat, love the fit

Get your music on with the small true wireless earbuds that feel lighter, fit better, and sound great. You get up to 24 hours of play time and textured ear tips that keep the buds comfortably in place, even if you're wearing them all day.

### True wireless earbuds. Essential comfort.

- Great sound from the tiny buds that fit like a dream
- Comfy SecureFit ear tips and large 10 mm drivers
- Bluetooth® multipoint connectivity and easy pairing
- Pocket-sized charging case with lanyard hole\*
- Compatible with Bluetooth® 6.0 and Microsoft Swift Pair

### Simply all you need

- Philips Headphones app. Customise your experience
- Warm, natural sound. Philips sound signature
- GRS-certified recycled plastic. Responsible packaging

### Take your tunes. Make your calls.

- Up to 24 hours of play time with the case
- Clear calls. They'll hear what you're saying
- IPX4 splash and sweat resistant


# Highlights

## Small earbuds, great sound



SecureFit textured ear tips bring you a fit that feels lighter and more comfortable, while creating a good seal for even better sound. Features like Dynamic Bass will let you enjoy the full power of your favourite tunes even if listening quietly.

## Bluetooth® 6.0

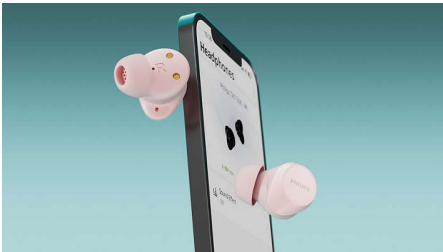

Compatibility with the latest Bluetooth® 6.0 devices lets you stream without annoying dips in the sound, and you can connect to two devices at once. Microsoft Swift Pair is supported too.

## Pocket-sized charging case



The small charging case slips easily into a pocket, or you can attach a strap to the lanyard hole\* and hang the case from your bag or belt loop. Mono mode means that you can use either earbud while the other one charges.

## Philips Headphones app

Feel like your music's missing something? Our companion app features AI Neural EQ, an intuitive equalizer that lets you tweak the sound and explore different EQ settings using your fingertips. You can also use the app to activate Dynamic Bass, manage connected devices, update firmware and more.

## Recycled materials

We use post-consumer recycled plastics in our products, and our packaging is made from FSC-certified recycled cardboard with inserts printed on recycled paper.

## IPX4 splash/sweat resistant

Never mind the weather, an IPX4 rating means that these earbuds are splash resistant so they don't mind a little rain! Wearing them during a quick workout or on a particularly hot day? They won't mind a little sweat either.

## 24 hours of play time with case

You get 6 hours of play time from a full charge, and an extra 18 hours from the case. Pop the earbuds back in the case and they'll recharge fully in 2 hours. If you need a quick boost, just 15 minutes gives you an extra hour. The case can be charged via USB-C.

## Clear calls

Your voice will come through clearly when you're on a call. A dedicated mic picks up the sound of your voice while a noise-reduction algorithm reduces some of the background noise from the world around you.

## Philips sound signature

The custom drivers in these headphones are tuned to the Philips sound signature, which brings you warm, natural sound with deep bass. Whatever you're listening to, you'll love what you hear.

# Specifications

## Sound

Acoustic system: Closed  
Frequency range: 20 - 20,000 Hz  
Speaker diameter: 10 mm  
Impedance: 16 Ohm  
Maximum power input: 10 mW  
Sensitivity: 105 dB (-10 dBFS, 1 kHz)  
Driver type: Dynamic

## Connectivity

Bluetooth version: 6.0  
Bluetooth profiles: A2DP, AVRCP, HFP  
Maximum range: Up to 10 m  
Supported codec: SBC

## Outer Carton

Length: 23.50 cm  
Number of consumer packages: 24  
Width: 21.70 cm  
Gross weight: 2.45 kg  
Height: 20.50 cm  
GTIN: 1 48 95229 17696 3  
Net weight: 1.18 kg  
Tare weight: 1.27 kg

## Convenience

Water resistance: IPX4  
Philips Headphones app support  
Mono mode for TWS  
Firmware updates possible  
Type of controls: Touch  
Microsoft Swift Pair

## Inner Carton

Length: 11.00 cm  
Number of consumer packages: 3  
Width: 10.10 cm  
Height: 9.00 cm  
Net weight: 0.15 kg  
Gross weight: 0.27 kg  
Tare weight: 0.12 kg  
GTIN: 2 48 95229 17696 0

## Power

Number of batteries: 3 pcs  
Music play time: 6 + 18 hour(s)  
Charging time: 2 hour(s)  
Fast charging time: 15 mins for 1 hr  
Battery type (Charging case): Lithium Polymer (built-in)  
Battery type (Earbud): Lithium Polymer (built-in)  
Battery weight (Total): 10.1 g  
Battery capacity (Case): 410 mAh  
Battery capacity (Earbud): 50 mAh

## Packaging dimensions

Height: 9.6 cm  
Packaging type: Carton  
Type of shelf placement: Hanging  
Width: 9.6 cm  
Depth: 3.35 cm  
Number of products included: 1  
EAN: 48 95229 17696 6  
Gross weight: 0.073 kg  
Net weight: 0.049 kg  
Tare weight: 0.024 kg

## Accessories

Quick Start Guide  
Eartips: 3 pairs (S/M/L)  
Charging case

## Design

Colour: Pink  
Ear coupling material: Silicone  
Ear fitting: In-ear  
In-ear fitting type: Silicone ear-tip

## Telecommunication

Microphone for call: 1 mic

## Dimensions

Charging case dimension (W x D x H): 3.83 x 2.65 x 5.73 cm  
Earbud dimension (W x D x H): 1.51 x 2.16 x 1.87 cm  
Total weight: 0.034 kg

## UPC

UPC: 8 40063 20786 8

## Voice assistant

Voice assistant compatible: Apple Siri, Google Assistant  
Voice assistant activation: Multi-Function touch  
Voice assistant support

## Sustainability

Plastic shell: contains 64% GRS certified recycled post-consumer Polycarbonate TE-00132492

