


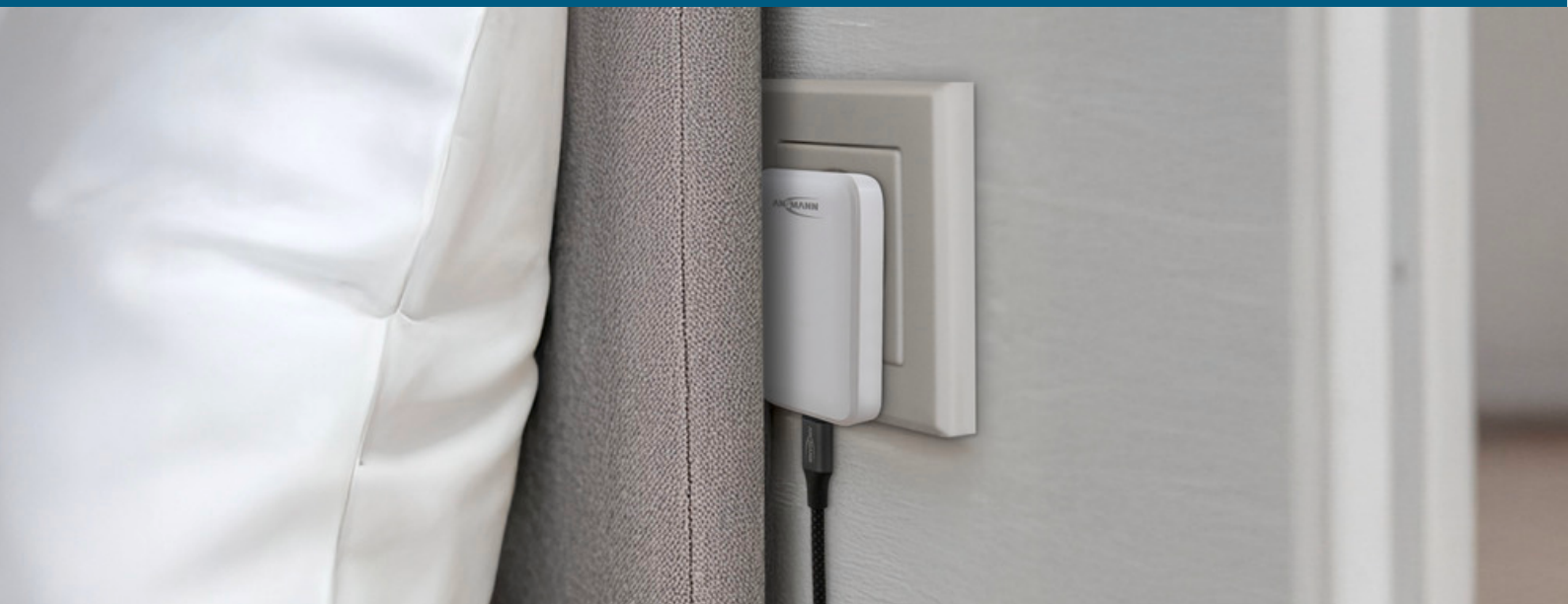

ANSMANN USB-C Wall Charger 130PD

Functional and flat charger with 30 W for smartphones, tablets and other USB devices.

Features

- USB charger with USB ports and 30 W
- Ideal for sockets behind furniture thanks to compact design
- Protects charging cables, preventing kinking
- Intelligent charge controller ensures optimum charging
- Multisafe technology protects both your end-device and the charger
- Universal compatibility: suitable for devices that are charged or operated via USB
- Input: 100 - 240V AC Wide-range input enables worldwide use
- Voltage range: 5V DC
- Power: 30 W



Power



Ultra fast charging



Low Self Discharge



for notebooks & phones



Gallium nitride
technology



Multisafe Technology



Power Delivery



Article number: 1001-0173

Product content: USB-C Wall Charger 130PD, manual



Specifications

Output voltage	5V DC		
Input voltage	100 - 240V AC		
Max. output current	3 A		
Max. input current	0.7 A		
Charging currents	Voltage	Max. current	Max. power
	5,0 V	3,0 A	15,0 W
	9,0 V	3,0 A	27,0 W
	12,0 V	2,5 A	30,0 W
	15,0 V	2,0 A	30,0 W
	20,0 V	1,5 A	30,0 W
Port	USB type C		
Maximum power	30 W		
Average operational efficiency	81,4 %		
Efficiency at low load	78,5 %		
Power consumption at no load	0,100 W		
Charging protocol	Power Delivery Profile 3 / PPS / Quick Charge 3.0		
Color	black		
Packaging	cardboard box		
Operating temperature	-5 - 25 °C		
Storage temperature	-20 - 70 °C		
Dimensions	65.6 × 50.9 × 42.5 mm		