
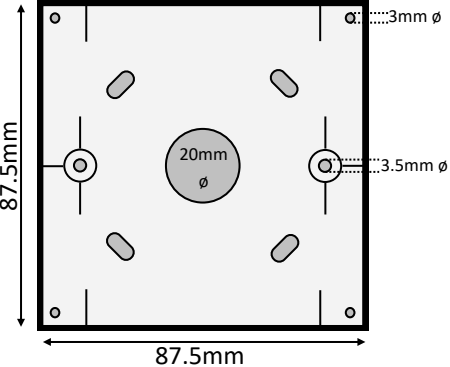
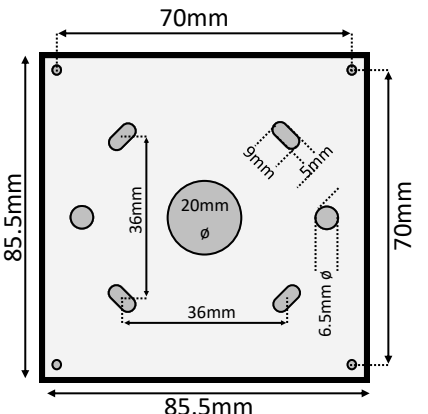
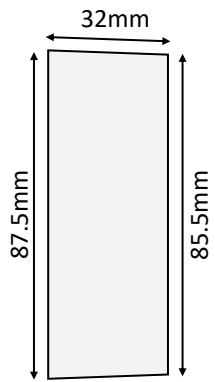
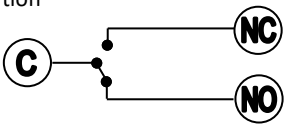
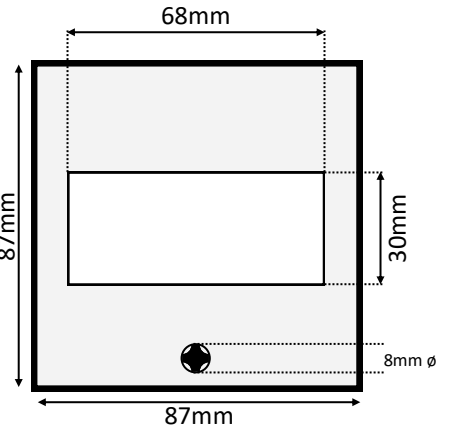
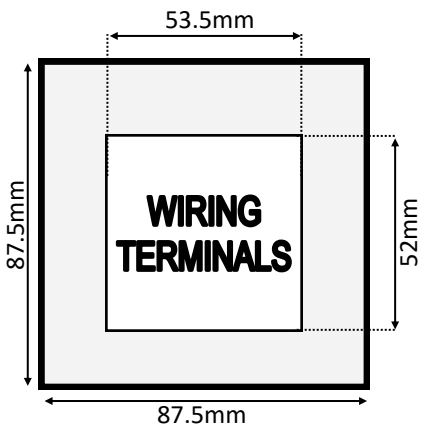


BACK BOX	FRONT VIEW  87.5mm 87.5mm 20mm ϕ 3.5mm ϕ 3mm ϕ	REAR VIEW  70mm 85.5mm 70mm 20mm ϕ 3.5mm ϕ 36mm 36mm 9mm 5mm 6.5mm	SIDE VIEW  32mm 87.5mm 85.5mm	DESCRIPTION Green Surface Call Point POLES 2—Double pole unit Common, N/O, N/C wiring on each pole as below Diagram shows call point in set, untriggered position  ACTIVATION Microswitch/Resettable Plate Microswitch/'Like glass' Insert Key provided WATERPROOFING None LED None TEMPERATURE RANGE -40 to +85 degrees Celcius ELECTRICALLY RATED AS FOLLOWS Max 50 Volts DC 50 Volts DC/5A 12.5 Volts DC/5A 250 Volts AC/3A
CALL POINT FRONT	 87mm 87mm 30mm 8mm ϕ 68mm	 53.5mm 87.5mm 52mm 87.5mm WIRING TERMINALS	 10mm 87mm 21.5mm 52mm 87.5mm WIRING TERMINALS	All dimensions in mm Do not scale CE © Knight Fire & Security Products Ltd All cases of infringement will be pursued.

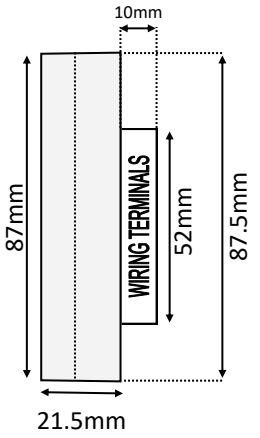

KNIGHT
FIRE & SECURITY

Unit 84 Seawall Road Ind. Estate
Cardiff UK CF24 5TH
Tel: +44 (0) 2920 488 129
Fax: +44(0) 2920 489 132

Drawing #: MX74
Drawn: Gareth Carpenter
Date: 01/04/2017
Revision: 3

NOTES REGARDING PART CODES:

The MX74 can be produced to various specifications. Use the below table as a guide on how the part code will affect the end product:

EXAMPLES:

MX74SYSC: Single pole surface call point in yellow, resettable, with cover
 MX74SG: Single pole surface call point in green, break plate, no cover

	S / F	W/G/Y/B/R	S	C
MX74	Surface	White	Resettable plate	With cover
		Green		
	Flush	Yellow	If omitted: Breakable plate	If omitted: Without Cover
		Blue		
		Red		




CALL POINT FRONT



CALL POINT REAR

NOTE: SINGLE POLE VARIANT SHOWN

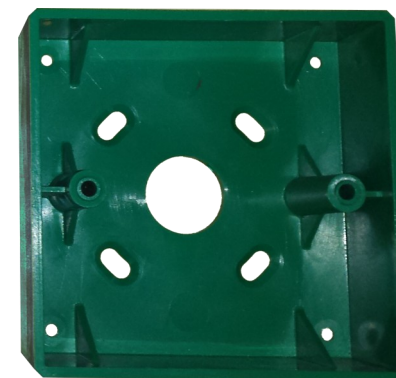

CALL POINT BACK BOX



KNIGHT
FIRE & SECURITY

Unit 84 Seawall Road Ind. Estate
 Cardiff UK CF24 5TH
 Tel: +44 (0) 2920 488 129
 Fax: +44(0) 2920 489 132

Drawing #: MX74
 Drawn: Gareth Carpenter
 Date: 01/04/2017
 Revision: 3

All dimensions in mm
 Do not scale



© Knight Fire & Security Products Ltd
 All cases of infringement will be pursued.