

Finishes

-  Stainless Steel
-  Marine Grade Black
-  Polished Brass



CL500

Heavy Duty Mechanical Access

The CL500 range features heavy-duty mechanical locks with large, full-size lever handles, making them ideal as primary door locks in high-traffic environments.

Designed for flexibility, the CL500 range offers multiple access options—manage entry using a key, code, or code-free mode to suit your needs. On mortice lock models, engaging the deadbolt restricts code access when required. For added safety, the internal lever handle always retracts the deadbolt, preventing accidental lock-ins. Additionally, front and back plates are available for seamless integration with existing locks.

FEATURES

- Large full size lever handles
- Ball knob/Stubby lever handle option available
- Code Free access options
- Two part 8mm ($\frac{5}{16}$ ") spring loaded spindle
- 2,047 non sequential code combinations available
- Suitable for internal and external use
- Medium duty latch with 'anti-shim' plunger
- Suitable for wooden doors 35mm - 60mm thick
- Large three coil lever return spring for high traffic use
- Neoprene seals included
- Locks will fit doors hung on the left or right
- Compatible with PINGuard™ XT2 weather cover
- Euro profile mortice sash with deadbolt and latchbolt
- Codelocks tubular lock/latch component CE-certified
- Codelocks FireKit Packs can be fitted to latch for 30 or 60 minute timber doorsets - Tested in accordance with BS EN 1634-1

LOCK MODELS



Front and Back Plates

Front and back plates only. Use with existing tubular mortice latch or lock. Existing lock must have a fixing hole 22mm ($\frac{7}{8}$ ") below follower (spindle).

Tubular Mortice Latch

Medium duty tubular mortice latch with 'anti-shim' plunger. Latch retracts by turning inside handle freely, or the outside handle after code input.

Back to Back Option (BB)

Medium duty tubular mortice latch. Two coded plates for installation on both sides of the door. Provides coded access in both directions.

Mortice Lock

Euro profile mortice sash lock with deadbolt and latchbolt. With the deadbolt thrown it denies access.

ADDITIONAL FEATURES

Code Free Access

The CL505, CL515 and CL525 models provide a Code Free option. The outside lever will retract the latch freely until disabled. To reset press the 'Y' button followed by the 'C' button.

Panic Kit Option

An extra long spindle is provided to work with most single point panic pads or bars.

Split Follower

The CL520 and CL525 Mortice Lock models utilise a split follower as a safety feature. This enables the inside lever to retract the deadbolt and latchbolt, after the deadbolt has been thrown, to prevent an accidental lock in.

Ball Knob

Ball Knob handle options available.

Marine Grade

Selected CL500 models are also available in a Black, Marine Grade finish. Salt spray test up to 1000 hours.

Mechanical Code Change Video

Scan the QR code to learn how to change your mechanical code



Easy to install



Suitable for wooden doors



Limited lifetime guarantee¹


2,047

Total code combinations


Mechanical Range

PRODUCT DIMENSIONS


CL510/CL515

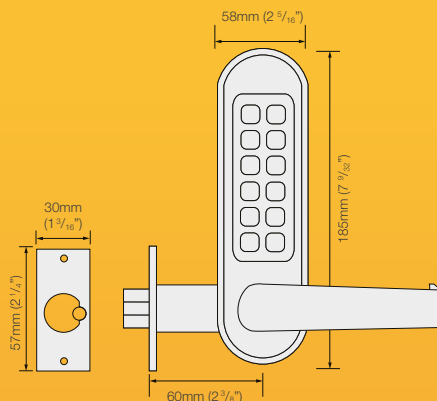


CL520/CL525

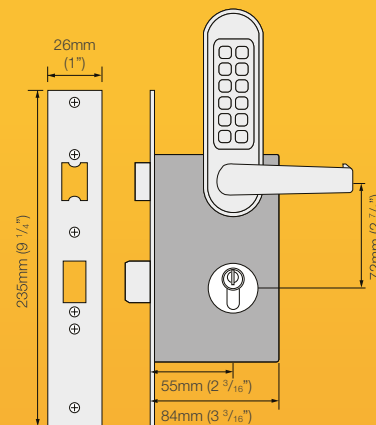

 Two Tubular Mortice Latch Sizes Available



Requires
25mm x 82mm
(1" x 3 1/4") hole

 

Requires
25mm x 92mm
(1" x 3 5/8") hole