

Finishes

-  Stainless Steel
-  Marine Grade Black
-  Polished Brass



CL400

Lever Handle Mechanical

The CL400 range offers medium-duty mechanical locks with full-size lever handles, providing an ideal solution for environments where knob-operated locks aren't practical.

Designed for flexibility, the CL400 range supports various access options — manage entry using a key, code, or code-free access. For greater control, the mortice lock models feature a deadbolt that can be thrown to restrict code access when necessary. Safety is a priority, with an internal lever handle that always retracts the deadbolt to prevent accidental lock-ins. Additionally, front and back plates are available, making it easy to integrate with existing locks. Choose the CL400 Mechanical Lock for practical, reliable access management.

FEATURES

- Full size lever handles with return to door
- PVD low maintenance finish
- Code Free access options
- Suitable for internal and external use
- Suitable for wooden doors 35mm - 60mm thick
- Euro profile mortice sash with deadbolt and latchbolt
- Medium duty latch with 'anti-shim' plunger
- Tumbler alignment for easy code change
- Neoprene seals included
- 8,191 non sequential code combinations available
- Two part 8mm ($\frac{5}{16}$ ") spring loaded spindle
- CodeLocks tubular latch component CE-certified
- CodeLocks FireKit Packs can be fitted to latch for 30 or 60 minute timber doorsets - Tested in accordance with BS EN 1634-1

LOCK MODELS



Front and Back Plates

Front and back plates only. Use with existing tubular mortice latch or lock. Existing lock must have a fixing hole 22mm ($\frac{7}{8}$ ") below follower (spindle).

Tubular Mortice Latch

Medium duty tubular mortice latch with 'anti-shim' plunger. Latch retracts by turning inside handle freely, or the outside handle after code input.

Back to Back Option (BB)

Medium duty tubular mortice latch. Two coded plates for installation on both sides of the door. Provides coded access in both directions.

Mortice Lock

Euro profile mortice sash lock with deadbolt and latchbolt. With the deadbolt thrown it denies access to code users. Supplied with Euro profile cylinders and three keys.

ADDITIONAL FEATURES

Code Free Access

The CL405, CL415 and CL425 models provide a Code Free option. These models feature a black dot on the 'Y' button. When the 'Y' button is pressed along with a correct code input, the lever will retract the latch freely until disabled. To reset press the 'Y' button followed by the 'C' button.

Split Follower

The CL420 and CL425 Mortise Lock models utilise a split follower as a safety feature. This enables the inside lever to retract the deadbolt and latchbolt, after the deadbolt has been thrown, to prevent an accidental lock in.

Marine Grade

Selected CL400 models are also available in a black, Marine Grade finish. Salt spray tested up to 1000 hours.

Code Change Method

Requires removal of the lock from the door. The code can be changed by repositioning the tumblers in the code chamber. Locks are supplied with a random code commencing with the 'C' clear button.

Mechanical Code Change Video

Scan the QR code to learn how to change your mechanical code



Easy to
install



Suitable for
wooden doors



Limited lifetime
guarantee¹


8,191

Total code
combinations


Mechanical Range

PRODUCT DIMENSIONS


CL410/CL415

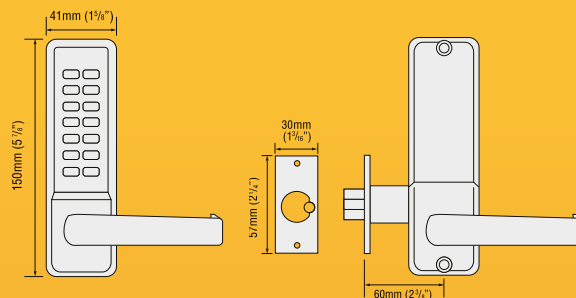


CL420/CL425

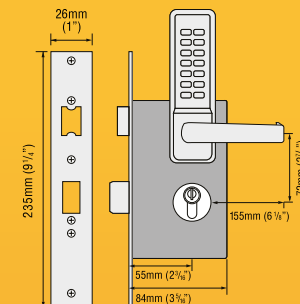

 Two Tubular Mortise Latch Sizes Available



Requires
25mm x 82mm
(1" x 3 1/4") hole

 

Requires
25mm x 92mm
(1" x 3 7/8") hole