

Category 5e Keystone Mount Coupler



Category 5e Unshielded Compact Keystone Mount Coupler (FACK4bk)

Features

- High performance data throughput, meets Category 5e data transfer rates
- POE Compliant
- Designed to fit wide range of keystone outlets, adaptors and patch panels
- Compatible with our 16 and 24 port keystone patch panels available with or without cable management
- Supplied with dustcover

Specifications

- Dimensions: **FACK4bk**: 29.5 x 16.9 x 21.8mm **FACK4bk#24**: 280 x 70 x 35mm
- Weight: **FACK4bk**: 6 grams **FACK4bk#24**: 138 grams
- Housing: ABS UL94V-0
- Contacts: 50µ"/ 1.27µm gold plating over nickel plated phosphor bronze
- Colour: Black

Packaging:

Supplied in individual polythene bags, then in bags of 20. To save time for panel assemblers, FACK4bk#24 is available as a "bulk pack" of 24 pieces without individual bags

Commodity Code: 85444920

EAN Number: FACK4bk – 5055386507624

FACK4bk#24 – 5055386507631

FACK4Dpm – 5055386507686

FACK4Bpm – 5055386509406

Country of origin: China

FACK4bk is available in D UNIVERSAL and Low Profile Panel Mount Versions









FACK4Dpm



FACK4Bpm

ROHS Compliant

Code: FACK4bk

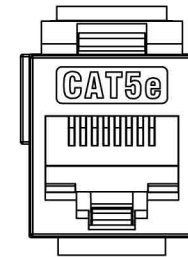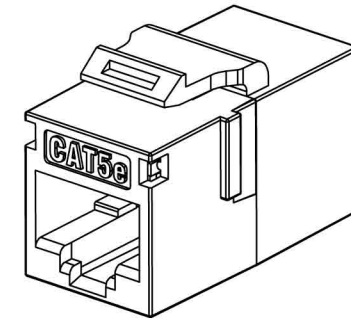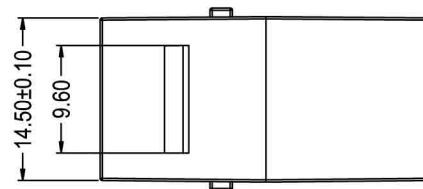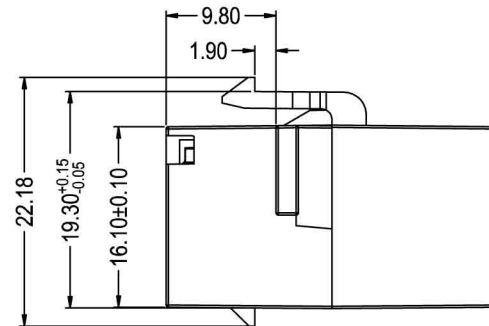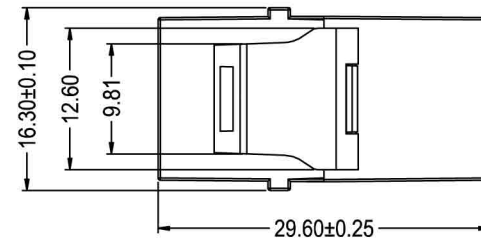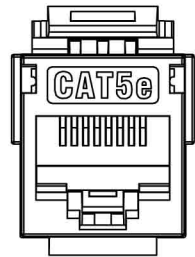

ELECTRICAL:

Current rating : 1.5A
 Dielectric withstanding voltage : 1000V/AC 60Hz
 Insulation resistance : 500 MΩ MIN.
 Contact resistance : 20 mΩ MAX.


MECHANICAL:

Durability:RJ45 With 750 Mating Cycles
 and RJ11 With 200 Mating Cycles
 Operating Temperature:-40°C to +85°C
 Storage Temperature:-40°C to +85°C

MATERIAL:

Front cover: ABS+PC V0
 RJ45 Jack Contact:Phosphor bronze,50U" Gold Plating

Category 5e Keystone Mount Coupler

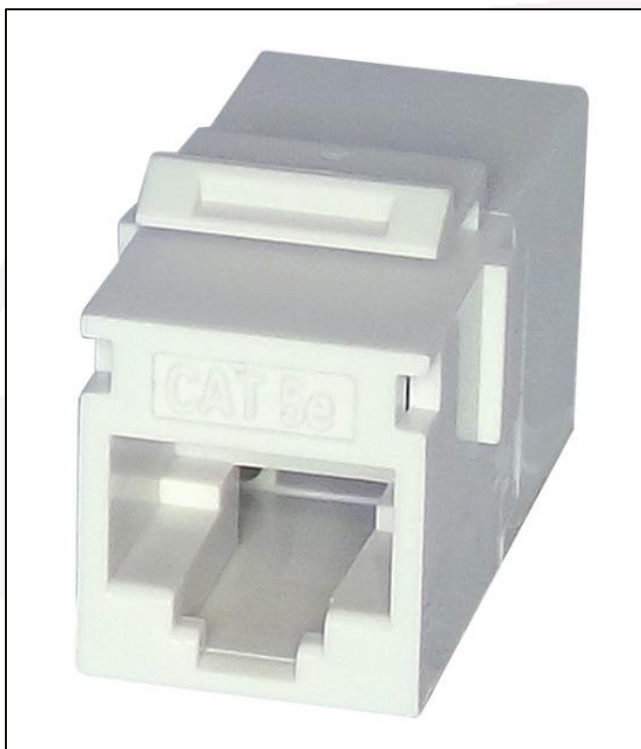

Category 5e Unshielded Compact Keystone Mount Coupler (FACK4wh)

Features

- High performance data throughput, meets Category 5e data transfer rates
- Designed to fit industry standard keystone outlets and patch panels
- Compatible with our 16 and 24 port keystone patch panels available with or without cable management

Specifications

- Dimensions: FACK4wh: 29.5 x 16.9 x 21.8mm (LxWxH) (LxWxH)
- Weight: FACK4: 6 grams
- Housing: ABS UL94V-0
- Contacts: 50µ"/ 1.27µm gold plating over nickel plated phosphor bronze
- Colour: White

Packaging:

- Supplied in individual polythene bags, then in bags of 20.


Commodity Code: 85444920

EAN Number: FACK4wh - 5055386507709

Country of origin: China

ROHS Compliant

Code: FACK4wh

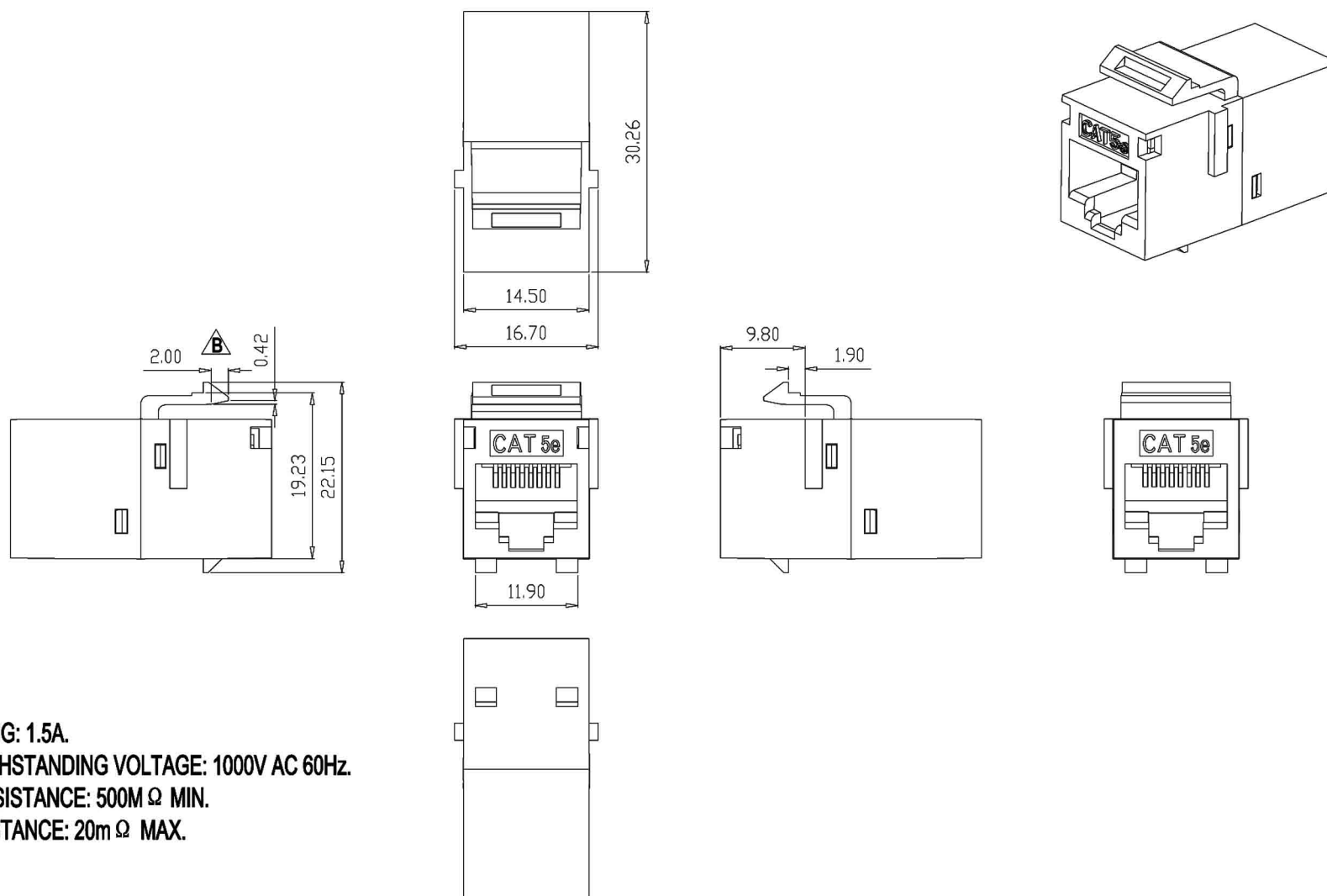

ELECTRICAL

CURRENT RATING: 1.5A.
DIELECTRIC WITHSTANDING VOLTAGE: 1000V AC 60Hz.
INSULATION RESISTANCE: 500M Ω MIN.
CONTACT RESISTANCE: 20m Ω MAX.

MECHANICAL

- (1) Materials: ABS+PC V0
- (2) RJ45 Jack Contact: 50 μ "/ 1.27 μ m gold plating over nickel plated phosphor bronze