


Sockets

MSEB 2630 S 1,9 Au

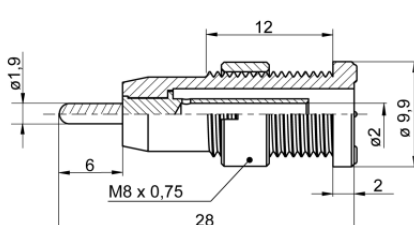

Product	MSEB 2630 S 1,9 Au
description	Miniature - safety built-in socket, 2 mm diameter, touch protected, 1,9mm soldering spike connection, gold-plated brass. For installation into switch- panels and equipment chassis with a wall thickness up to 8mm. Installation hole: 8mm diameter
operating instruction	BA254
article-no. / *colour	9754597xx  00 black  01 red  02 blue  03 yellow  04 green  05 brown  06 gray  07 white  09 violet  88 yellow/green
drawing	
technical data	
connection	solder connection
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	10 A
material socket	brass, gold plated
housing material	PA
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	V-2
UL	cURus E537895

2 mm safety system

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
stand : November 13, 2025 6:00 PM