


Clamp-type test probe

KLEPS 3 ST

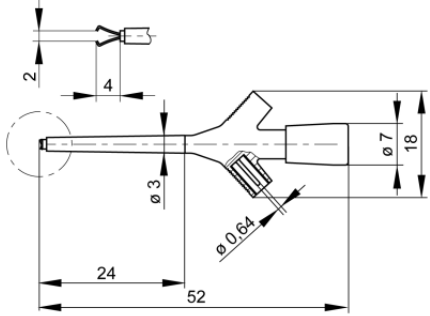

Product	KLEPS 3 ST
description	Miniature clamp-type test probe with rotating grip jaws. Suitable for very thin wires and densely packed contacts. Connects with MKL... and MAL...
operating instruction	BA002
article-no. / *colour	● 00 black ● 01 red
drawing	
	
technical data	
connection	unsprung pin Ø 0.64 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	2 A
material plug	brass, gold plated
housing material	PBT
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
clamp type	rotating grip jaws, tin plated

0.64 mm system

clamping range	2 mm
----------------	------

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM