


Test probes

PRUEF 3

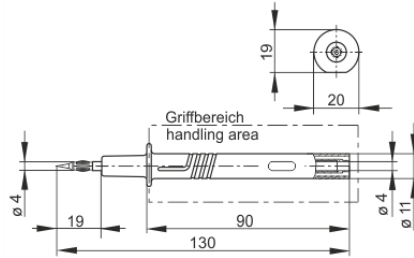

Product	PRUEF 3
description	Test probe with dual function. Tip for penetrating insulation and oxide layers and 4 mm diameter pin for insertion in sockets. 4 mm diameter brass socket connection. Connects with 4 mm measuring leads (standard and safety system). Tip protection included.
operating instruction	BA419
article-no. / *colour	9733691xx  00 black  01 red
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	32 A
material socket	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 6:00 PM