
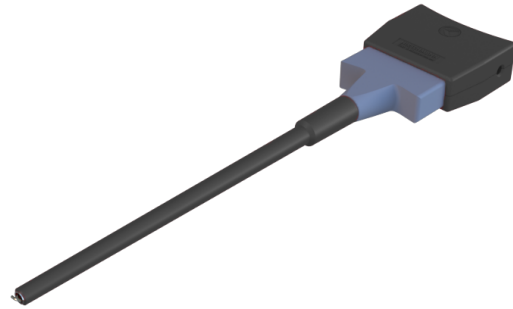


Clamp-type test probe

KLEPS 60

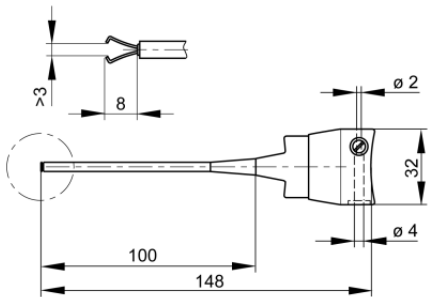

Product	KLEPS 60
description	Clamp-type test probe grip jaws and flexible shaft. The special form of the grip jaws permits clamping of pins and wires up to a maximum of 4 mm diameter. 4 mm diameter brass socket connection with additional screw connection, grip jaws additionally tin-plated.
operating instruction	BA408
article-no. / *colour	● 00 black ● 01 red
drawing	
	
technical data	
connection	4 mm socket (unsprung) screw terminal
rated voltage	30 VAC / 60 VDC
measurement cat. acc. to IEC 61010	O ⁽²⁾
rated current (consider derating curve)	4 A
material socket	brass
housing material	PP, PS
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

4 mm safety system

clamp type	grip jaws, tin plated
clamping range	4 mm

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

⁽²⁾without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 5:59 PM