


Crocodile clips

AK 2 B 2540 I

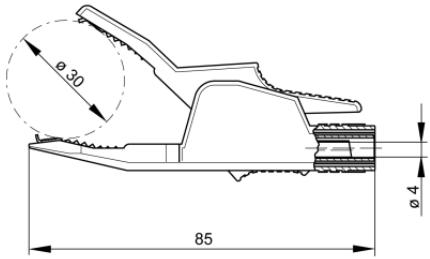

Product	AK 2 B 2540 I
description	Contact-protected, high-strength, wide-opening alligator clip. Clamping range up to 30mm bolt diameter. Solid wire clip, U-shaped and fine wire section. Nickel-plated brass connecting socket, pluggable with 4mm safety measuring leads.
operating instruction	BA465
article-no. / *colour	9724051xx  00 black  01 red  02 blue  03 yellow  04 green  88 yellow/green
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	32 A
material socket	brass, nickel plated
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-30 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

clamping range	30 mm
----------------	-------

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges

stand : November 13, 2025 5:59 PM