
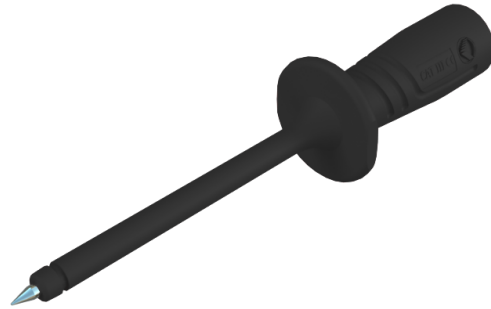


Test probes

PRUEF 2600

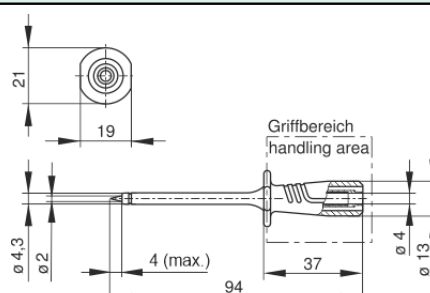

Product	PRUEF 2600
description	Test probe with shatter-proof insulating sleeve and slender stainless steel tip. Tip for penetration of oxide layers. 4 mm diameter brass socket connection. Connects with safety measuring leads.
operating instruction	BA464
article-no. / *colour	9723171xx  00 black  01 red
drawing	
	
technical data	
connection	unsprung socket 4 mm
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT III
rated current (consider derating curve)	1 A
material socket	brass
housing material	PP
temperature range acc. To IEC61010 ⁽¹⁾	-25 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
 stand : November 13, 2025 6:00 PM