
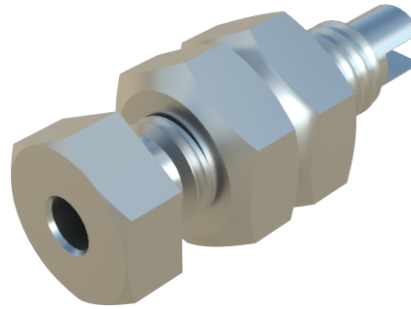


## Sockets

### MBU 10

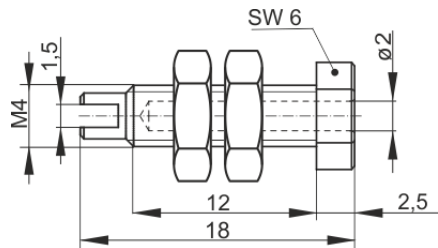

| Product                                           | MBU 10                                                                                                                                                                   |
|---------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| description                                       | Unsprung 2 mm built-in socket, compatible with 2 mm spring-loaded plug. Suitable for installation in equipment chassis and switch panels up to a wall thickness of 6 mm. |
| operating instruction                             | BA205                                                                                                                                                                    |
| Articlenumber                                     | 938441000                                                                                                                                                                |
| drawing                                           |                                                                                                                                                                          |
|                                                   |                                                                                       |
| technical data                                    |                                                                                                                                                                          |
| connection                                        | M4 thread, solder connection                                                                                                                                             |
| rated voltage                                     | 30 VAC / 60 VDC                                                                                                                                                          |
| measurement cat. acc. to IEC 61010                | O <sup>(2)</sup>                                                                                                                                                         |
| rated current<br>(consider derating curve)        | 6 A                                                                                                                                                                      |
| material socket                                   | brass, nickel plated                                                                                                                                                     |
| temperature range acc. To IEC61010 <sup>(1)</sup> | -15 °C to +100 °C                                                                                                                                                        |

<sup>(1)</sup>contact the manufacturer for applications at deviating temperature ranges

<sup>(2)</sup>without rated measurement category, for other circuits that are not directly connected to mains

stand : November 13, 2025 6:00 PM