


Measuring leads

PL 2700 S W

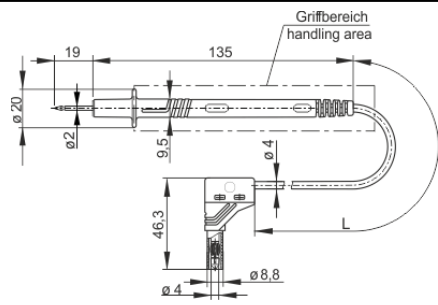

Product	PL 2700 S W
description	Safety test lead with test probe. Tip for penetration of oxide layers and 4 mm diameter safety connector with right-angled outlet. Highly flexible, double insulated stranded lead, shatter-proof grip sleeve and lead. Built in color indicator for easy identification of insulation damages.
operating instruction	BA452
article-no. / *colour	9341551xx  00 black  01 red
drawing	
	
technical data	
rated voltage	AC/DC 1000 V
measurement cat. acc. to IEC 61010	CAT II
rated current (consider derating curve)	16 A
material plug	brass, nickel plated
housing material	PA, PP
temperature range acc. To IEC61010 ⁽¹⁾	-15 °C to +70 °C
flammability class acc. to UL 94 (only valid for basic material of housing)	HB
cable length	100 cm
conductor size	1 mm ²

4 mm safety system

⁽¹⁾contact the manufacturer for applications at deviating temperature ranges
stand : November 13, 2025 5:59 PM